

Rectangular hinge, drilled or countersunk


CHA

Sheet metal with rolled knuckle



- Universal hinge for plug door
- Material:
 - Stainless steel 304
- Natural finish

Advantages

- Economic hinge

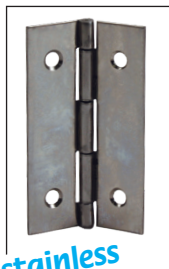

stainless
steel

 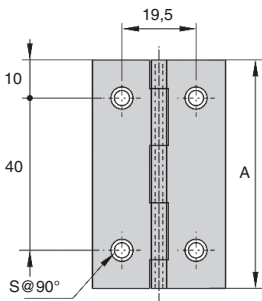

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	S	Type	Weight (g)	Stock*	Price each 1 to 5
CHA60-35-F/SS	60	35	1	2	4	Countersunk	20	✓	6,22 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



PTA40ssEB
Articulated foot whit
sheet metal base
Ø40, Ø 40



PR820
Idle sprocket for slat
top chain, Rangs 820
and 815



HG8-ECO
Eco range Spur gear,
Steel C45



EFTC
Fixing support,
Stainless steel




MET
Cylindrical sintered
bronze bush, Self-
lubricating sintered
bronze



BAG-MI
Split shaft collar with
clamp lever, Steel



 PR125
Articulated foot Ø123,
Ø 123



PF40NM
Worm and wheel gear
reducer, up to 18 Nm



LBE
Miniature closed
linear bearing,



RBNpl
Swivel castor with
plate, Steel - rubber



DOMI30
Domino 30 adjustable
slide, Slide DOMILINE



LC
Friction clutch, 30 to
240 Nm

Complementary products



CHAC4040SS
Square hinge with
riveted pin, drilled,
Square with riveted
pin, dri...



CHAC4040NP
Square hinge with
riveted pin, not
drilled, Square with
riveted pin,...