

Rectangular hinge, drilled or countersunk


CHA

Sheet metal with rolled knuckle



- Universal hinge for plug door
- Material:
 - Stainless steel 304
- Natural finish

Advantages

- Economic hinge

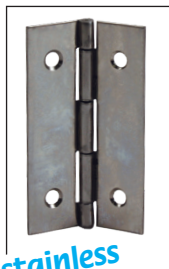

stainless steel

 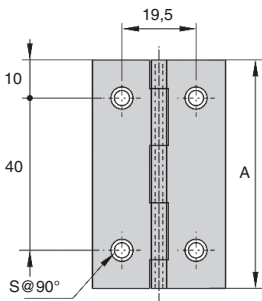

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	A	B	C	ØD	S	Type	Weight (g)	Stock*	Price each 1 to 5
CHA60-35-F/SS	60	35	1	2	4	Countersunk	20	✓	6,22 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

 
Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



Q3

Double row angular contact ball bearing, Angular contact - Steel



CHB

Worm and wheel gear reducer, up to 41 Nm



CABPVC

PVC covered galvanised steel cable, Galvanised steel with



CHTRP

Single and dual output gearboxes, Up to 87,3 Nm



CHA35

Hinge for aluminium profile, Hinge



VTAP

Magnetic head screw, With rubber coating With rubber coating



CHINV

Invisible hinge, Invisible - 90° opening



PRES7HR

Manual workbench press, Force up to 700kg



JCSs

Single stainless steel universal joint, Low



NSR

Adjustable clamp, Adjustable



MCLred

Reducing sleeve female/female,



MDR

Dee shackle with eye bolt, Steel

Complementary products



CHAC4040SS

Square hinge with riveted pin, drilled, Square with riveted pin, dri...



CHAC4040NP

Square hinge with riveted pin, not drilled, Square with riveted pin,...