

# Rectangular hinge, drilled or countersunk


## CHA

## Sheet metal with rolled knuckle



- Universal hinge for plug door
- Material:
  - Stainless steel 304
- Natural finish

### Advantages

- Economic hinge

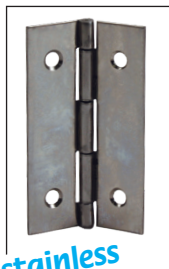

stainless  
steel

 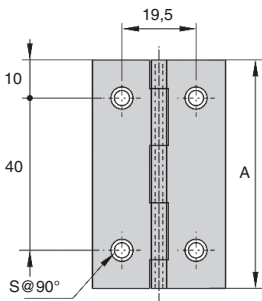

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	A	B	C	ØD	S	Type	Weight (g)	Stock*	Price each 1 to 5
CHA60-35-F/SS	60	35	1	2	4	Countersunk	20	✓	6,22 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000

Service 0,15 €/min + prix appel

## Our other products



E60

Right angle helical reducers, from 4.50 to 62 Nm



BPPE

Ball transfer unit push fit, Light



H5E-H5B

Hexagonal spacer, Brass



RCC\_RCX

Spherical tilt washer - DIN6319, concave



KB\_OP

Open precision linear bearing, Precision - steel



ZDB

Machined plastic bevel gear , 2:1



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



HRV

V-rail guidance Simple Select® system, Rail with carriage



PRF\_T

Corner reinforcement, Corner reinforcement



FF20

Offset spur gear reducer, from 5.80 to 220 Nm



LF

Precision locknut, Precision locknut



ES

Bipod support base, Plastic

## Complementary products



CHAC4040SS

Square hinge with riveted pin, drilled, Square with riveted pin, drilled, dri...



CHAC4040NP

Square hinge with riveted pin, not drilled, Square with riveted pin,...