



 

Square hinge with riveted pin, **not drilled**

Sheet metal with rolled knuckle **CHAC-NP**

- Hinge for plug door
- Riveted pin, leaves not offset
- Material:
CHAC-NP: Steel hinge
CHAC-NP/SS: Stainless steel 304
- Natural finish

Advantages

- Economic hinge

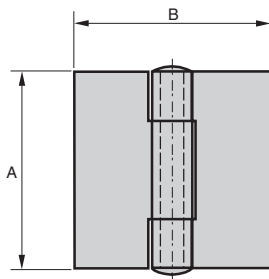


DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each 1 to 5
Steel							
CHAC4040-NP	40	40	2	4	34	✓	8,69 €
CHAC5050-NP	50	50	2	6	61	✓	10,68 €
CHAC6060-NP	60	60	2	6	82	✓	11,80 €
Stainless steel							
CHAC4040-NP/SS	40	40	2	4	34	✓	14,69 €
CHAC5050-NP/SS	50	50	2	6	61	✓	16,85 €
CHAC6060-NP/SS	60	60	2	6	82	✓	19,03 €

*Depending on availability - Dimensions in mm

 Our other products



LAT4
4A motorised linear
actuator, 4 amperes



WINGbrEcrou
Manually tightened
wing nut DIN315,
Brass DIN 315



PRF JL2
Lip seal for panel,
Door seal - Ø 2mm



AK
Bellows coupling
Gerwah®, from 36 to
800Nm




SCH
Horizontal hook
toggle clamp,
Horizontal Hook
clamp - stainless steel



PSG15
Spur gear - precision
range, Stainless steel
316



NSA
Adjustable clamp,
Articulated

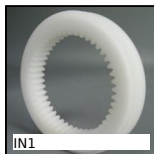

IN1
Internal gear,
Machined plastic
(delrin)



ACLEPP
Right angled bracket
for aluminium profile,



PTAF80-PAMF80
Articulated fixable
foot with pressed



AT5M AT10M
AT type timing belt
per metre, AT10 Steel



ES
Simple support base
(bipod), Plastic

Complementary products



CHAC4040NP
Square hinge with
riveted pin, not
drilled, Square with
riveted pin,...



CHAC4040SS
Square hinge with
riveted pin, drilled,
Square with riveted
pin, dri...