



 

Square hinge with riveted pin, **not drilled**

Sheet metal with rolled knuckle **CHAC-NP**

- Hinge for plug door
- Riveted pin, leaves not offset
- Material:
 - CHAC-NP:** Steel hinge
 - CHAC-NP/SS:** Stainless steel 304
- Natural finish

Advantages

- Economic hinge

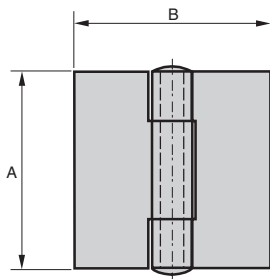

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each
						1 to 5	
Steel							
CHAC4040-NP	40	40	2	4	34	✓	8,69 €
CHAC5050-NP	50	50	2	6	61	✓	10,68 €
CHAC6060-NP	60	60	2	6	82	✓	11,80 €
Stainless steel							
CHAC4040-NP/SS	40	40	2	4	34	✓	14,69 €
CHAC5050-NP/SS	50	50	2	6	61	✓	16,85 €
CHAC6060-NP/SS	60	60	2	6	82	✓	19,03 €

*Depending on availability - Dimensions in mm

Our other products



TBE16

Economic mini-table with trapezoidal leadscrew, 5kg



ALIDRP240

24V DC power supply, 10 A



SHA_PT

Handwheel with handle, Polyamide



RPCtcss

Swivel castor with central hole, Stainless steel - Polyamide



CTZY

Diabolo shaped elastomount, Steel



MCL

Cylindrical threaded sleeve, Cylindrical - stainless steel




WJUM10

Drylin® W bearing block, Slide



VLBS

 Folding lifting ring for welding, Folding - for welding



PF40

Worm and wheel gear reducer, up to 18 Nm



BAB

Hardened Stainless steel ball pin, Stainless steel



PCLA_T

Technopolymer clamping lever - male, Plastic



RAS

90° ball and socket joints DIN71802, Stainless steel

Complementary products



CHAC4040NP

Square hinge with riveted pin, not drilled, Square with riveted pin,...



CHAC4040SS

Square hinge with riveted pin, drilled, Square with riveted pin, dri...