

Rectangular hinge, drilled or countersunk

CHA

Sheet metal with rolled knuckle



- Universal hinge for plug door
- Material:
 - Stainless steel 304
- Natural finish

Advantages

- Economic hinge



stainless
steel

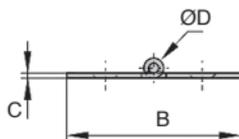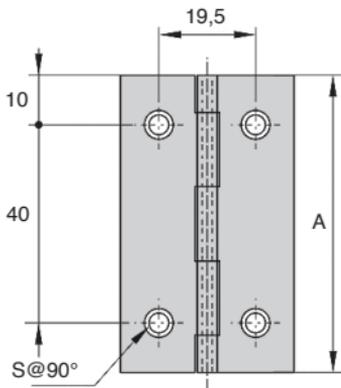

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | ØD | S | Type | Weight (g) | Stock* | Price each 1 to 5 |
|---------------|----|----|---|----|---|-------------|------------|--------|-------------------|
| CHA60-35-F/SS | 60 | 35 | 1 | 2 | 4 | Countersunk | 20 | ✓ | 6,41 € |

*Depending on availability - Dimensions in mm



Square hinge with riveted pin, **not drilled**

Sheet metal with rolled knuckle **CHAC-NP**

 

- Hinge for plug door
- Riveted pin, leaves not offset
- Material:
 - CHAC-NP:** Steel hinge
 - CHAC-NP/SS:** Stainless steel 304
- Natural finish

Advantages

- Economic hinge



Steel or stainless steel

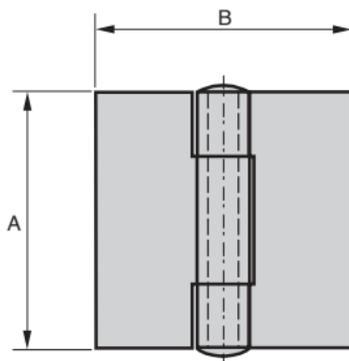

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | ØD | Weight (g) | Stock* | Price each 1 to 5 |
|------------------------|----|----|---|----|------------|--------|-------------------|
| | | | | | | | |
| Steel | | | | | | | |
| CHAC4040-NP | 40 | 40 | 2 | 4 | 34 | ✓ | 10,32 € |
| CHAC5050-NP | 50 | 50 | 2 | 6 | 61 | ✓ | 12,80 € |
| CHAC6060-NP | 60 | 60 | 2 | 6 | 82 | ✓ | 15,59 € |
| Stainless steel | | | | | | | |
| CHAC4040-NP/SS | 40 | 40 | 2 | 4 | 34 | ✓ | 17,62 € |
| CHAC5050-NP/SS | 50 | 50 | 2 | 6 | 61 | ✓ | 20,76 € |
| CHAC6060-NP/SS | 60 | 60 | 2 | 6 | 82 | ✓ | 25,18 € |

*Depending on availability - Dimensions in mm

Square hinge with riveted pin, drilled Eco

CHAC Sheet metal with rolled knuckle

 

- Hinge for plug door
- Riveted pin, half swaged
- Material:
Stainless steel 304
- Natural finish

stainless steel



Advantages

- Economic hinge

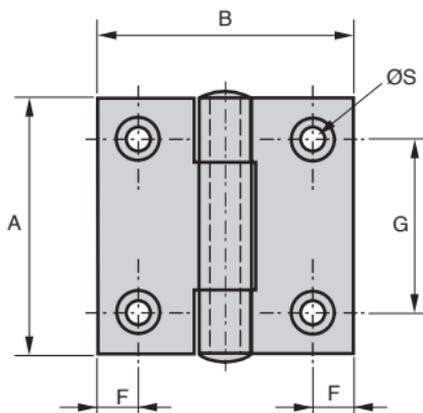

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |


| Part number | A | B | C | ØD | F | G | ØS | Weight (g) | Stock* | Price each 1 to 5 |
|-------------|----|----|---|----|---|----|-----|------------|--------|-------------------|
| CHAC4040/SS | 40 | 40 | 2 | 4 | 8 | 24 | 3,5 | 34 | ✓ | 8,63 € |
| CHAC5050/SS | 50 | 50 | 2 | 6 | 8 | 34 | 4,0 | 61 | ✓ | 10,70 € |
| CHAC6060/SS | 60 | 60 | 2 | 6 | 8 | 40 | 4,0 | 82 | ✓ | 11,89 € |

*Depending on availability - Dimensions in mm



- **Hinge for hatch opening**
- Its integrated stop avoids the need to add an external stop or a safety bracket
- Materials :
316 stainless steel

Advantages

- Ideal for horizontal use. When it reaches its stop, the hatch is held open under its own weight

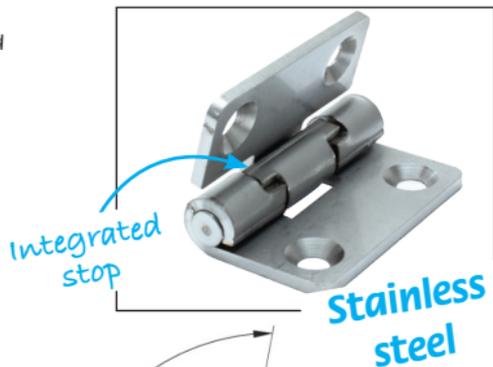

Typical application

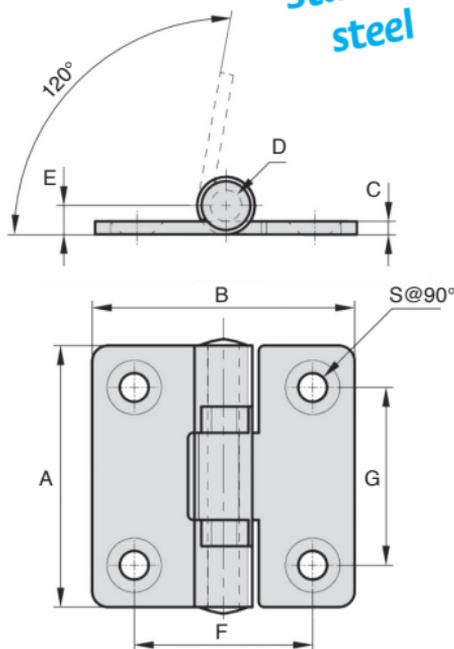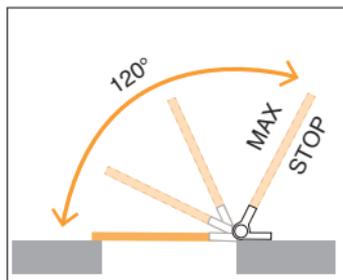

DISCOUNT

| | | | | |
|-------|------|------|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -10% | -20% | On request |

| Part Number | A | B | C | D | E | F | G | S | Weight (g) | Stock* | Price each 1 to 5 |
|--------------|----|----|-----|---|-----|----|----|-----|------------|--------|-------------------|
| CHAB50-50/SS | 50 | 50 | 2,5 | 6 | 5,5 | 34 | 34 | 5,5 | 70 | ✓ | 20,99 € |

*Depending on availability - Dimensions in mm