

# Square hinge with riveted pin, **drilled**

## CHAC Sheet metal with rolled knuckle

 

- Hinge for plug door
- Riveted pin, half swaged
- Material:  
Stainless steel 304
- Natural finish

stainless steel



### Advantages

- Economic hinge

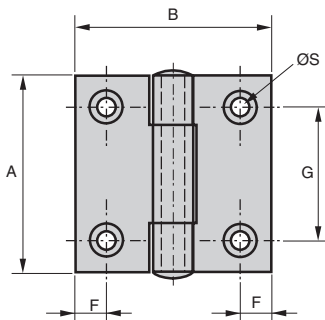

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	F	G	ØS	Weight (g)	Stock*	Price each 1 to 5
CHAC4040/SS	40	40	2	4	8	24	3,5	34	✓	14,69 €
CHAC5050/SS	50	50	2	6	8	34	4,0	61	✓	17,45 €
CHAC6060/SS	60	60	2	6	8	40	4,0	82	✓	19,89 €

\*Depending on availability - Dimensions in mm



 

# Square hinge with riveted pin, **not drilled**

## Sheet metal with rolled knuckle **CHAC-NP**

- Hinge for plug door
- Riveted pin, leaves not offset
- Material:
  - CHAC-NP:** Steel hinge
  - CHAC-NP/SS:** Stainless steel 304
- Natural finish

### Advantages

- Economic hinge

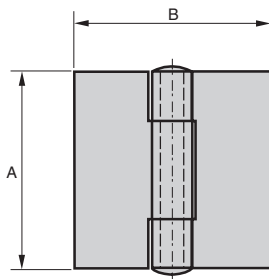

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each
						1 to 5	
<b>Steel</b>							
CHAC4040-NP	40	40	2	4	34	✓	8,69 €
CHAC5050-NP	50	50	2	6	61	✓	10,68 €
CHAC6060-NP	60	60	2	6	82	✓	11,80 €
<b>Stainless steel</b>							
CHAC4040-NP/SS	40	40	2	4	34	✓	14,69 €
CHAC5050-NP/SS	50	50	2	6	61	✓	16,85 €
CHAC6060-NP/SS	60	60	2	6	82	✓	19,03 €

\*Depending on availability - Dimensions in mm

## Our other products



CHN\_CHN55  
Straight long link stainless steel chain, Stainless steel



WSS5s  
Symmetrical S shaped hook stainless steel, Stainless steel



DOM180  
Accessories, Plate




EKN  
Bellows coupling Gerwah®, from 0.5 to 12Nm



PCS37  
Chain sprocket - steel, 9.525mm (DIN06B-1)



 PRESSHR  
Manual workbench press, Force up to 500kg



PF15  
Worm and wheel gear reducer, up to 3,75 Nm




PRF\_PIV  
Internal hinge pin for aluminium profile, Internal hinge pin



MFBS  
Stainless steel flexible bellows coupling, Stainless steel - with



 PRS50  
Stainless steel articulated foot Ø50, Ø 50



T5M T10M  
T type timing belt per metre, T10 Steel cored polyurethane



CAP880  
Side flexing slim slat top chain acetal, Narrow range 880

## Complementary products



CHAC4040NP  
Square hinge with riveted pin, not drilled, Square with riveted pin,...



CHA60  
Rectangular hinge, drilled or countersunk, Rectangular, drilled or c...