

# Square hinge with riveted pin, drilled Eco

## CHAC Sheet metal with rolled knuckle

 

- Hinge for plug door
- Riveted pin, half swaged
- Material:  
Stainless steel 304
- Natural finish

stainless steel



### Advantages

- Economic hinge

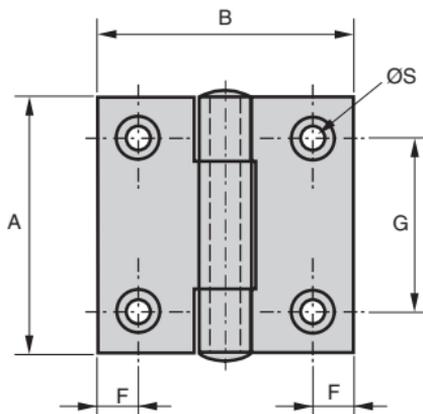

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	F	G	ØS	Weight (g)	Stock*	Price each 1 to 5
CHAC4040/SS	40	40	2	4	8	24	3,5	34	✓	14,69 €
CHAC5050/SS	50	50	2	6	8	34	4,0	61	✓	17,45 €
CHAC6060/SS	60	60	2	6	8	40	4,0	82	✓	19,89 €

\*Depending on availability - Dimensions in mm



 

# Square hinge with riveted pin, **not drilled**

## Sheet metal with rolled knuckle **CHAC-NP**

- Hinge for plug door
- Riveted pin, leaves not offset
- Material:
  - CHAC-NP:** Steel hinge
  - CHAC-NP/SS:** Stainless steel 304
- Natural finish

### Advantages

- Economic hinge

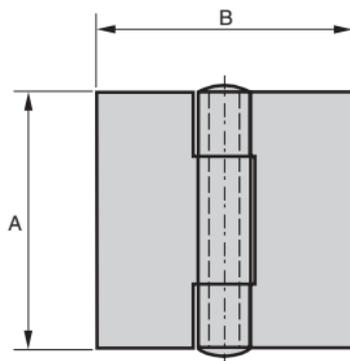

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each
						1 to 5	
<b>Steel</b>							
CHAC4040-NP	40	40	2	4	34	✓	8,69 €
CHAC5050-NP	50	50	2	6	61	✓	10,68 €
CHAC6060-NP	60	60	2	6	82	✓	11,80 €
<b>Stainless steel</b>							
CHAC4040-NP/SS	40	40	2	4	34	✓	14,69 €
CHAC5050-NP/SS	50	50	2	6	61	✓	16,85 €
CHAC6060-NP/SS	60	60	2	6	82	✓	19,03 €

\*Depending on availability - Dimensions in mm

## Our other products



HLC19  
Right angle spiro  
bevel gearbox, Up to  
43Nm



WJUM16  
Drylin® W bearing  
block, Slide



MSP19  
Masterplate®  
glueable insert Ø19,  
Cylindrical with  
tapped insert



FBL4004\_K7  
Brush strip per meter  
PA6 fibres Ø0.3 to  
Ø0.5, Black polyamide  
6 -...



F7-P-AM  
Multifunction display,  
Magnetic ring



CHAE4060PA  
Decorative  
asymmetric screwed  
hinge, Polyamide



TCL-ECL  
Support rod for heavy  
loads, Support spindle



VHTM  
Hexagonal headed  
screw Hygienic  
Design®, Stainless  
steel



DOG258  
Motor-gearbox 12V  
and 24V DC, from 12  
to 15 Nm



GLT3E-58  
Telescopic drawer,



BABFCFO  
Ball pin socket,  
Mounting collar with  
an oval flange



OP3\_14\_06  
Reducing sleeve for  
OP indicators,  
Reduction socket

## Complementary products



CHAC4040NP  
Square hinge with  
riveted pin, not  
drilled, Square with  
riveted pin,...



CHA60  
Rectangular hinge,  
drilled or countersunk,  
Rectangular, drilled or  
c...