

CHAE



Polyamide

Screwed hinge

- Materials :
hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 316L
- Asymetrical and symetrical versions available

Advantages

- Aesthetic design
- Max opening angle 270°

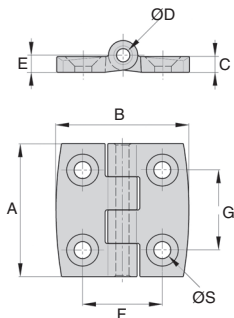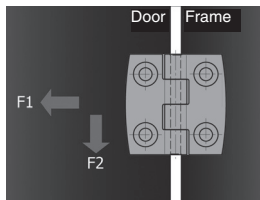

Part number	Tensile strength F1	Shear strength F2	Screw torque (Nm)
CHAE3030/PA	1200	850	1
CHAE4040/PA	2200	1900	4
CHAE5050/PA	3600	2100	8
CHAE6060/PA	5100	3100	8

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	ØS	For screw	Stock*	Price each 1 to 5
CHAE3030/PA	30	30	3	3	3,5	18	18	3,2	M3	✓	4,02 €
CHAE4040/PA	40	40	5,2	4	5,7	25	25	5,3	M4	✓	6,07 €
CHAE5050/PA	50	50	5,9	5	6,4	30	30	6,4	M6	✓	8,04 €
CHAE6060/PA	60	60	6,5	6	7	36	36	6,4	M6	✓	7,94 €

Dimensions in mm

Our other products



CHA1056-UPA
Molded polyamide
face-mounted hinge,
Black polyamide



PTA80
Articulated levelling
foot, pressed base
Ø80, Ø 80



DCA
Suction cup, 1.5
bellows, silicon




UGH40
H Type Guide units,
For Ø40 actuators



TBEBASE
Base plate for
economic mini-table,
Allows X-Y cross
tables



CNA-CNG
Right angled
mounting plate, Right
angled mounting
plate for clevis

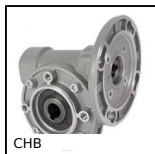

CHB
Worm and wheel gear
reducer, up to 73 Nm



DCA
Suction cup, 1.5
bellows, natural
rubber




VDSQ
Sliding lock
adjustment system,
Sliding lock for square



ACLRP
Wheel for aluminium
profile, Integrated
bearing



 PR85
Articulated foot Ø83,
Ø 83



PM4
Worm and wheel set,
Machined plastic
(delrin)

Complementary products



CHAE6555
Decorative screwed
hinge, Aluminium



CHAM527055
Marine hinge for
welding/screw
mounting, Marine



CHAEpac
Square decorative
screwed hinges,
carbon fibre
reinforced



CHA35
Hinge for aluminium
profile, Hinge