

CHAE



Polyamide

Screwed hinge

- Materials :
hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 316L
- Asymetrical and symetrical versions available

Advantages

- Aesthetic design
- Max opening angle 270°

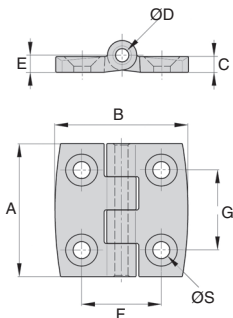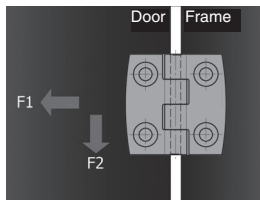

Part number	Tensile strength F1	Shear strength F2	Screw torque (Nm)
CHAE3030/PA	1200	850	1
CHAE4040/PA	2200	1900	4
CHAE5050/PA	3600	2100	8
CHAE6060/PA	5100	3100	8

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	ØS	For screw	Stock*	Price each 1 to 5
CHAE3030/PA	30	30	3	3	3,5	18	18	3,2	M3	✓	4,02 €
CHAE4040/PA	40	40	5,2	4	5,7	25	25	5,3	M4	✓	6,07 €
CHAE5050/PA	50	50	5,9	5	6,4	30	30	6,4	M6	✓	8,04 €
CHAE6060/PA	60	60	6,5	6	7	36	36	6,4	M6	✓	7,94 €

Dimensions in mm

Our other products



FAD
Threaded swivel feet,
Swivel feet without
anti-slip plate



PRF JL2
Lip seal for panel,
Door seal - Ø 2mm



PTMC
Telescopic furniture
foot, square plate



LRM2
Cylindrical bronze nut,
Bronze - 2 threads



DOMI50
Accessories, Clamping
lever



SDC
Positioning sleeve for
indexing pin, For pin
Ø4 to Ø12



ACL-PR
Joining plate for
aluminium profile,
Right angled
connection



SUP
Self-centering
clamping hub steel,
Without locknut



BCTH
Mushroom headed
button Hygienic
Usit®, With female



PSG15
Spur gear - precision
range, Pre-hardened
Steel 35NCD6



PPD
Indexing plunger for
sheets, For sheet
metal



CDR
Retaining cable for
ball pin, Retaining
cable

Complementary products



CHAE6555
Decorative screwed
hinge, Aluminium



CHAM527055
Marine hinge for
welding/screw
mounting, Marine



CHAEpac
Square decorative
screwed hinges,
carbon fibre
reinforced



CHA35
Hinge for aluminium
profile, Hinge