

## CHAE



## Polyamide

### Screwed hinge

- Materials :  
hinges glass fibre reinforced polyamide (30%)  
sealed pin : stainless steel 316L
- Asymetrical and symetrical versions available

### Advantages

- Aesthetic design
- Max opening angle 270°

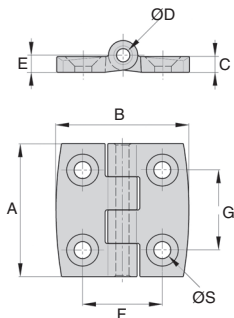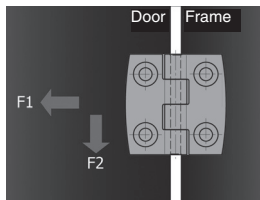

Part number	Tensile strength F1	Shear strength F2	Screw torque (Nm)
CHAE3030/PA	1200	850	1
CHAE4040/PA	2200	1900	4
CHAE5050/PA	3600	2100	8
CHAE6060/PA	5100	3100	8

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	ØS	For screw	Stock*	Price each 1 to 5
CHAE3030/PA	30	30	3	3	3,5	18	18	3,2	M3	✓	4,02 €
CHAE4040/PA	40	40	5,2	4	5,7	25	25	5,3	M4	✓	6,07 €
CHAE5050/PA	50	50	5,9	5	6,4	30	30	6,4	M6	✓	8,04 €
CHAE6060/PA	60	60	6,5	6	7	36	36	6,4	M6	✓	7,94 €

Dimensions in mm

## Our other products



PHG05  
Parallel axis helical gear - Precision range, 20NCD2 case hardened s...



BLHM50  
Right angled gearbox, double output shafts, up to 30 Nm



CHA135  
Screwed hinge, 135 degrees



DOMI80  
Accessories, Clamping lever



WJUM16  
Drylin® W bearing block, Slide



CHALss  
Piano hinge, Stainless steel



LVT  
Miniature motorised actuator 4A, 4 amperes



VQTplqn  
Quarter-turn clamp lock - Clamping plate, Flush mounting



AKD  
Bellows coupling Gerwah®, from 22 to 600Nm



SHA\_PT  
Handwheel with handle, Polyamide



PAMF120  
Articulated fixable foot, pressed bolt-down base Ø 120, Ø 120



EX  
Optional shaft for E-type gear reducers, E Gearboxes double sided ou...

## Complementary products



CHAE6555  
Decorative screwed hinge, Aluminium



CHAM527055  
Marine hinge for welding/screw mounting, Marine



CHAEpac  
Square decorative screwed hinges, carbon fibre reinforced



CHA35  
Hinge for aluminium profile, Hinge