

CHAE



Polyamide

Screwed hinge

- Materials :
hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 316L
- Asymetrical and symetrical versions available

Advantages

- Aesthetic design
- Max opening angle 270°

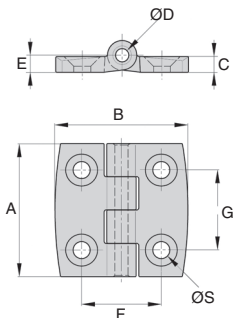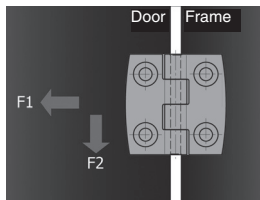

Part number	Tensile strength F1	Shear strength F2	Screw torque (Nm)
CHAE3030/PA	1200	850	1
CHAE4040/PA	2200	1900	4
CHAE5050/PA	3600	2100	8
CHAE6060/PA	5100	3100	8

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	ØS	For screw	Stock*	Price each 1 to 5
CHAE3030/PA	30	30	3	3	3,5	18	18	3,2	M3	✓	4,02 €
CHAE4040/PA	40	40	5,2	4	5,7	25	25	5,3	M4	✓	6,07 €
CHAE5050/PA	50	50	5,9	5	6,4	30	30	6,4	M6	✓	8,04 €
CHAE6060/PA	60	60	6,5	6	7	36	36	6,4	M6	✓	7,94 €

Dimensions in mm

Our other products



DOMI50

Domino 50 adjustable slide, Slide DOMILINE 50 with counter and handw...



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



TMR

Rigid manual tensioner, Adjustable



CLB_T

Die cast zinc clamping lever - male, Zamak



UGH20

H Type Guide units, For Ø20 actuators



HAR9

Captive C washer, DIN 6371



R205

Die spring ISO10243, Heavy



BOX-TOR-C

Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



GPBSS

Threaded spherical knob, Stainless steel 304



 
PLS

Cylindrical spacer, Stainless steel 303



SSB

Stainless steel bevel gear, 1:1



PRZ

Wear strip for slat top chain, Z profile to be clipped

Complementary products



CHAE6555

Decorative screwed hinge, Aluminium



CHAM527055

Marine hinge for welding/screw mounting, Marine



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced



CHA35

Hinge for aluminium profile, Hinge