

Decorative **asymmetric** screwed hinge

Pla

CHAE_A

Polyamide

- Screwed hinge

- Materials :




hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 316L

- Square and symmetrical versions also available

Advantage

- Aesthetic design

- Max opening angle 270°

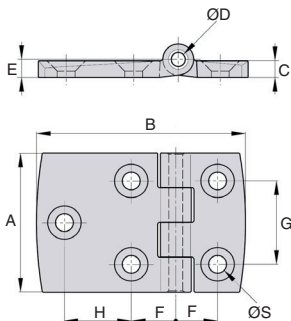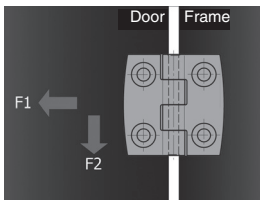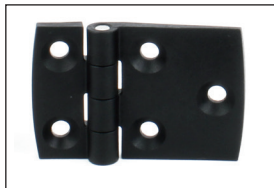

Part number	Tensile strength	Shear strength	Screw torque (Nm)
CHAE4060A/PA	2200	2300	4
CHAE4080A/PA	2200	2300	4
CHAE5075A/PA	3600	2500	8
CHAE6090A/PA	5100	4200	8

Dimensions en mm

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	H	ØS	For screw	Stock*	Price each
											1 to 5	
CHAE4060A/PA	40	60	5,2	4	5,7	13,5	25	19	5,3	M4	✓	7,94 €
CHAE4080A/PA	40	80	5,2	4	5,7	14,5	25	38	5,3	M4	✓	8,15 €
CHAE5075A/PA	50	75	5,9	5	6,4	16	30	24	6,4	M6	✓	10,09 €
CHAE6090A/PA	60	90	6,5	6	7	18	36	30	6,4	M6	✓	14,14 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



BLHB20

Right angled gearbox, bored shafts, up to 1.77 Nm



DIA

Ring operated locking bolt, with ring



PR40

Articulated foot Ø50, Ø 50



NCT

Square tube connector, Fixed angle



PMB

Anti-vibration machine mount, Oval base plate



AK

Bellows coupling Gerwah®, from 36 to 800Nm



SLS

Bearing block for leadscrew, Floating Drylin® bearing block



M0

Worm and wheel set, Unhardened steel



PR125

Articulated foot Ø123, Ø 123



PO

Pull handle - Multi-sector, Tapped



BTC_M

End cap with threaded insert for square tube,



BABV

Ball lock pins lockable, Stainless steel

Complementary products



CHAE6555

Decorative screwed hinge, Aluminium



CHAM527055

Marine hinge for welding/screw mounting, Marine



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced