

Decorative **asymmetric** screwed hinge

Pla

CHAE_A

Polyamide

- Screwed hinge

- Materials :




hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 316L

- Square and symmetrical versions also available

Advantage

- Aesthetic design

- Max opening angle 270°

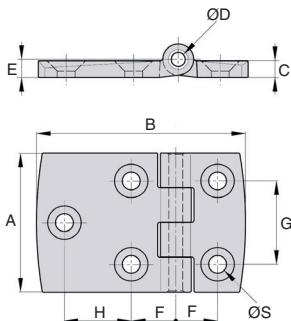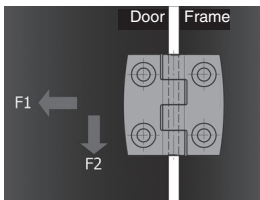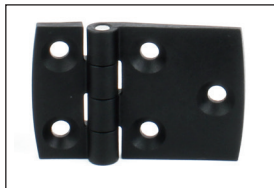

Part number	Tensile strength	Shear strength	Screw torque (Nm)
CHAE4060A/PA	2200	2300	4
CHAE4080A/PA	2200	2300	4
CHAE5075A/PA	3600	2500	8
CHAE6090A/PA	5100	4200	8

Dimensions en mm

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	H	ØS	For screw	Stock*	Price each
											1 to 5	
CHAE4060A/PA	40	60	5,2	4	5,7	13,5	25	19	5,3	M4	✓	7,94 €
CHAE4080A/PA	40	80	5,2	4	5,7	14,5	25	38	5,3	M4	✓	8,15 €
CHAE5075A/PA	50	75	5,9	5	6,4	16	30	24	6,4	M6	✓	10,09 €
CHAE6090A/PA	60	90	6,5	6	7	18	36	30	6,4	M6	✓	14,14 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



T10_21_AL

T type timing pulley,
Economy range - T10
aluminium



PCS62K

Chain sprocket with
hardened teeth,
15.875mm (DIN10B-1)



TBE16

Economic mini-table
with trapezoidal
leadscrew, 5kg



PRF4590_E

Bracket for aluminium
profile, PRF4590



ZHG6

Plastic spur gear,
Machined plastic
(delrin)



PTAF100-PAMF100

Articulated fixable
foot with pressed
base Ø100, Ø 100



CHA135

Screwed hinge, 135
degrees



AT5-BAR

AT type tooth bar
stock, AT5



PSG05HC

Skive hobbed spur
gears - precision



GLT3-76

Telescopic drawer,



SH1

Parallel axis helical
gear, Steel 20NCD2



GPBSS

Threaded spherical
knob, Aluminium

Complementary products



CHAE6555

Decorative screwed
hinge, Aluminium



CHAM5270SS

Marine hinge for
welding/screw
mounting, Marine



CHAEpac

Square decorative
screwed hinges,
carbon fibre
reinforced