

Decorative **asymmetric** screwed hinge

Pla

CHAE_A

Polyamide

- Screwed hinge

- Materials :




hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 316L

- Square and symmetrical versions also available

Advantage

- Aesthetic design

- Max opening angle 270°

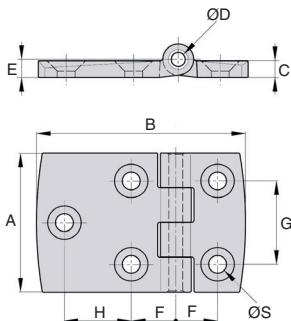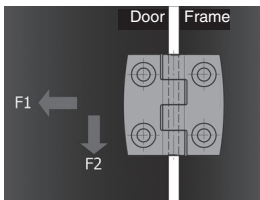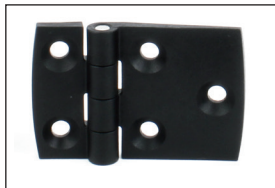

Part number	Tensile strength	Shear strength	Screw torque (Nm)
CHAE4060A/PA	2200	2300	4
CHAE4080A/PA	2200	2300	4
CHAE5075A/PA	3600	2500	8
CHAE6090A/PA	5100	4200	8

Dimensions en mm

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	H	ØS	For screw	Stock*	Price each
											1 to 5	
CHAE4060A/PA	40	60	5,2	4	5,7	13,5	25	19	5,3	M4	✓	7,94 €
CHAE4080A/PA	40	80	5,2	4	5,7	14,5	25	38	5,3	M4	✓	8,15 €
CHAE5075A/PA	50	75	5,9	5	6,4	16	30	24	6,4	M6	✓	10,09 €
CHAE6090A/PA	60	90	6,5	6	7	18	36	30	6,4	M6	✓	14,14 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



BPMc

Stainless steel slotted spring plunger with ceramic ball tip, 303 St...



gt64

Rotating bent lever, Common applications



MLY

Bow shackle with eye bolt, Steel



NPTR10

Adjustable cross clamp, Adjustable



ACM_AZ

Mounting bracket for bonnet fastener, Hook



BDM

Pin for magnetic bush, Fast and light magnetic locking



ADL_F

Female eye bolt conforms to DIN582, Stainless steel



CMAss

Eye bolt stainless steel, Stainless steel



ZB

Shaft for linear guides, Hardened



MLY_SS

Stainless steel bow shackle with eye bolt,



PR881

Idle sprocket for slat top chain, Range 881



UGH25

H Type Guide units, For Ø25 actuators

Complementary products



CHAE6555

Decorative screwed hinge, Aluminium



CHAM527055

Marine hinge for welding/screw mounting, Marine



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced