

Decorative **asymmetric** screwed hinge

Pla

CHAE_A

Polyamide

- Screwed hinge

- Materials :




hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 304

- Square and symmetrical versions also available

Advantage

- Aesthetic design

- Max opening angle 270°

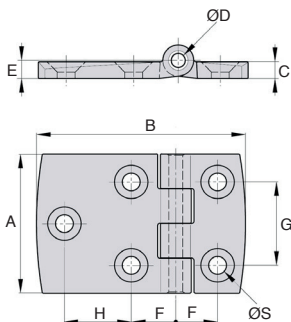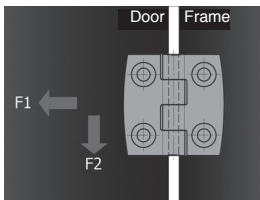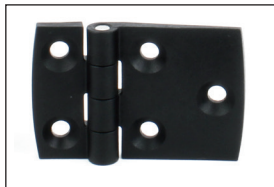

| Part number | Tensile strength | Shear strength | Screw torque (Nm) |
|--------------|------------------|----------------|-------------------|
| CHAE4060A/PA | 2200 | 2300 | 4 |
| CHAE4080A/PA | 2200 | 2300 | 4 |
| CHAE5075A/PA | 3600 | 2500 | 8 |
| CHAE6030A/PA | 5100 | 4200 | 8 |

Dimensions en mm

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | A | B | C | ØD | E | F | G | H | ØS | For screw | Stock* | Price each |
|--------------|----|----|-----|----|-----|------|----|----|-----|-----------|--------|------------|
| | | | | | | | | | | | 1 to 5 | |
| CHAE4060A/PA | 40 | 60 | 5,2 | 4 | 5,7 | 13,5 | 25 | 19 | 5,3 | M4 | ✓ | 7,87 € |
| CHAE4080A/PA | 40 | 80 | 5,2 | 4 | 5,7 | 14,5 | 25 | 38 | 5,3 | M4 | ✓ | 8,08 € |
| CHAE5075A/PA | 50 | 75 | 5,9 | 5 | 6,4 | 16 | 30 | 24 | 6,4 | M6 | ✓ | 10,00 € |
| CHAE6090A/PA | 60 | 90 | 6,5 | 6 | 7 | 18 | 36 | 30 | 6,4 | M6 | ✓ | 14,01 € |

Dimensions in mm

 
HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



T0

Torsion spring,
Stainless steel



FB_ECO

Eco. range steel bevel
gear, 4:1



ACM_AZ

Mounting bracket for
bonnet fastener, Hook



HLA19

Right angle spiro
bevel gearbox, Up to
43Nm



J66

Spur gear coaxial
gearbox, from 0.90 to
2.80 Nm - Inline



 
BEAB

Knob star grip
antibacterial, Star,
anti-bacterial



SLH-M

Nut for toggle clamp,
Round ended nut for
SLH/SLV clamp




G0

Steel spur gear, Steel
20NCD2




GMK17_BR

 Clamp for guiding
profile, Rounded only
- double



BCM_HPBT

 Modular cylindrical
brush, PBT polyester
bristles



ACL-PLAngle

Joining plate for
aluminium profile,
Angle connection



SHA_PTR

Handwheel with
folding handle,
Polyamide

Complementary products



CHAE6555

Decorative screwed
hinge, Aluminium



CHAM527055

Marine hinge for
welding/screw
mounting, Marine