

# Plastock Symmetrical decorative screwed hinge

Polyamide



CHAE

## Screwed hinge

- Material :  
hinges glass fibre reinforced polyamide (30%)  
sealed pin : stainless steel 316L
- Corrosion resistant
- Square and asymmetrical versions available

## Advantages

- Aesthetic design
- Max opening angle 270°

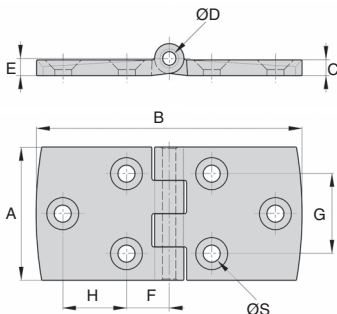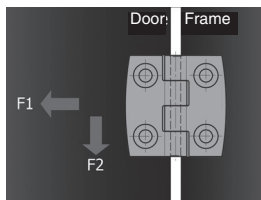

Part number	Tensile strength F1	Shear strength F2	Screw torque (Nm)
CHAE4080/PA	2200	1900	4
CHAE40120/PA	2200	1900	4
CHAE50100/PA	3600	2100	8
CHAE60120/PA	5100	3100	8

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	H	ØS	For screw	Stock*	Price each
											1 to 5	
CHAE4080/PA	40	80	5,2	4	5,7	13,5	25	19	5,3	M4	✓	8,16 €
CHAE40120/PA	40	120	5,2	4	5,7	14,5	25	38	5,3	M4	✓	10,09 €
CHAE50100/PA	50	100	5,9	5	6,4	16	30	24	6,4	M6	-	10,37 €
CHAE60120/PA	60	120	6,5	6	7	18	36	30	6,4	M6	✓	16,53 €

Dimensions in mm

## Our other products



DPAR\_DKON  
Progressive stop,  
Steel



UFX  
Spare tyre UNEFLEX®  
coupling, range



WFRM  
Flanged polymer nut,  
Polymer (Iglidur®) - 1  
thread



BC2  
Panamech, Multi-  
Beam, Aluminium -  
with clamping jaw



TBbutee  
Axial thrust bearing,  
Steel balls



HTD14M\_85  
HTD Heavy duty  
timing pulley, HTD14  
Steel



PSG15  
Spur gear - precision  
range, Case hardened  
steel 20NCD2



BOXINS300  
Box set of self tapping  
inserts, Boxed set -  
For hard materials



BOX-TOR-A  
Box set of Nitrile O-  
rings in nitrile, 2.90 x  
1.78mm to 28.17 x  
3.53



FF10  
Offset spur gear  
reducer, from 0.78 to  
3.70 Nm



CHTRP  
Single and dual  
output gearboxes, Up  
to 87,3 Nm



MFB  
Flexible bellows  
coupling, Aluminium  
and Bronze - With set  
screw

## Complementary products



CHAE6555  
Decorative screwed  
hinge, Aluminium



CHAM527055  
Marine hinge for  
welding/screw  
mounting, Marine



CHAEpac  
Square decorative  
screwed hinges,  
carbon fibre  
reinforced