

# Plastock Symmetrical decorative screwed hinge

Polyamide



CHAE

## Screwed hinge

- Material :  
hinges glass fibre reinforced polyamide (30%)  
sealed pin : stainless steel 316L
- Corrosion resistant
- Square and asymmetrical versions available

## Advantages

- Aesthetic design
- Max opening angle 270°

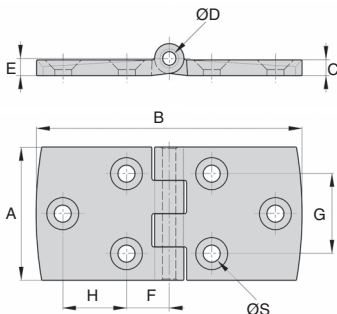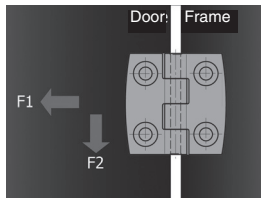

Part number	Tensile strength F1	Shear strength F2	Screw torque (Nm)
CHAE4080/PA	2200	1900	4
CHAE40120/PA	2200	1900	4
CHAE50100/PA	3600	2100	8
CHAE60120/PA	5100	3100	8

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	H	ØS	For screw	Stock*	Price each
											1 to 5	
CHAE4080/PA	40	80	5,2	4	5,7	13,5	25	19	5,3	M4	✓	8,16 €
CHAE40120/PA	40	120	5,2	4	5,7	14,5	25	38	5,3	M4	✓	10,09 €
CHAE50100/PA	50	100	5,9	5	6,4	16	30	24	6,4	M6	-	10,37 €
CHAE60120/PA	60	120	6,5	6	7	18	36	30	6,4	M6	✓	16,53 €

Dimensions in mm

## Our other products



BIMSS

Indexing plunger mini, miniature - Stainless steel



SHWbr

Washer - DIN125, Brass



F7-SF-SM

Multifunction display, Mounting bracket for front mounting



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



BOX-TOR-H

Box set of Nitrile O-rings in nitrile, 3.00 x 2.00mm to 45.20 x 4.00



PRF\_PGN

Door handle for aluminium profile, Handle with lock suitable



 
BAG-MI

Split shaft collar with clamp lever, Steel



GSI\_A

Stainless steel adjustable gas spring, Stainless steel



LAT1

1A motorised linear actuator, 1 ampere



SHTP

Drylin® Linear table, Economy range



RCC\_RCX

Spherical tilt washer - DIN6319, concave



BCM\_T

Driving collar, Driving collar

## Complementary products



CHAE6555

Decorative screwed hinge, Aluminium



CHAM527055

Marine hinge for welding/screw mounting, Marine



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced