

Plastock Symmetrical decorative screwed hinge

Polyamide



CHAE

Screwed hinge

- Material :
hinges glass fibre reinforced polyamide (30%)
sealed pin : stainless steel 304
- Corrosion resistant
- Square and asymmetrical versions available

Advantages

- Aesthetic design
- Max opening angle 270°

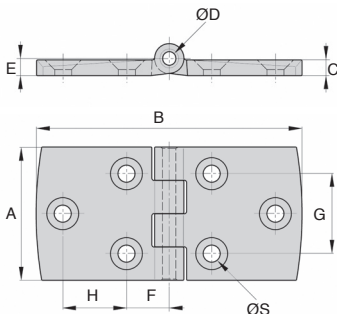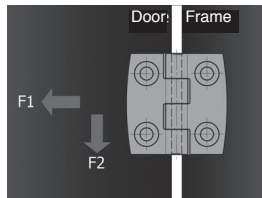

Part number	Tensile strength F1	Shear strength F2	Screw torque (Nm)
CHAE4080/PA	2200	1900	4
CHAE40120/PA	2200	1900	4
CHAE50100/PA	3600	2100	8
CHAE60120/PA	5100	3100	8


DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	H	ØS	For screw	Stock*	Price each
											1 to 5	
CHAE4080/PA	40	80	5,2	4	5,7	13,5	25	19	5,3	M4	✓	8,09 €
CHAE40120/PA	40	120	5,2	4	5,7	14,5	25	38	5,3	M4	✓	10,00 €
CHAE50100/PA	50	100	5,9	5	6,4	16	30	24	6,4	M6	-	10,28 €
CHAE60120/PA	60	120	6,5	6	7	18	36	30	6,4	M6	✓	16,38 €

Dimensions in mm

 Our other products



PRT

Slewing ring bearing
Iglidur®, Iglidur®,
aluminium and
stainless steel



SHA_PT

Hand wheel,
Polyamide



PRF-P

Foot support, For feet
or casters



CHT56

3 phase AC
asynchronous motor,
0.09kW



CTss

Universal joint,
telescopic, stainless
steel, industrial



ZBconique

Machined plastic
bevel gear (delrin),
1:1



GRP2-14-C

Spring pin, splined
ISO 8742



PGMhuss

Carrying handle
Hygienic Usit®,
Stainless steel



GPB

Threaded spherical
knob, With brass
insert



CHA138

Screw-in hinge, 138
degrees



MSP38

Masterplate®
glueable insert,
Cylindrical Ø38 with



OP7

Numerical counter (No
of turns), 5 numbers

Complementary products



CHAE6555

Decorative hinges,
Aluminium



CHAM527055

Hinge (stainless
steel), Marine