

# Plastock Symmetrical decorative screwed hinge

Polyamide



CHAE

## Screwed hinge

- Material :  
hinges glass fibre reinforced polyamide (30%)  
sealed pin : stainless steel 304
- Corrosion resistant
- Square and asymmetrical versions available

## Advantages

- Aesthetic design
- Max opening angle 270°

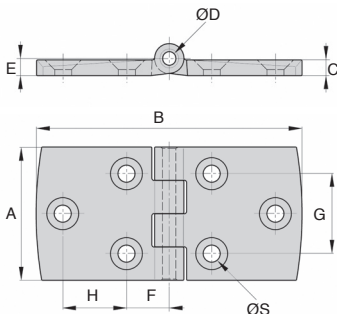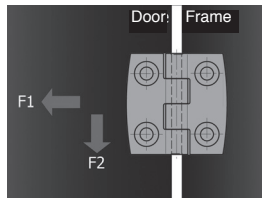

Part number	Tensile strength F1	Shear strength F2	Screw torque (Nm)
CHAE4080/PA	2200	1900	4
CHAE40120/PA	2200	1900	4
CHAE50100/PA	3600	2100	8
CHAE60120/PA	5100	3100	8

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	E	F	G	H	ØS	For screw	Stock*	Price each
											1 to 5	
CHAE4080/PA	40	80	5,2	4	5,7	13,5	25	19	5,3	M4	✓	8,09 €
CHAE40120/PA	40	120	5,2	4	5,7	14,5	25	38	5,3	M4	✓	10,00 €
CHAE50100/PA	50	100	5,9	5	6,4	16	30	24	6,4	M6	-	10,28 €
CHAE60120/PA	60	120	6,5	6	7	18	36	30	6,4	M6	✓	16,38 €

Dimensions in mm


## Our other products



DOMI30  
Accessories, Plate



 BPHF  
Ball transfer unit push fit, Heavy



H0  
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



CHAFR-MINI  
Miniature friction hinge, Miniature friction hinge



ZBconique  
Machined plastic bevel gear, 1:1



PRT-TO  
igidur® slewing ring, With external teeth- Iglidur®, aluminium & S...



UCFL  
Cast iron flanged bearing, Cast iron



DOMI80  
Accessories, Plate



VMS  
Stainless steel knurled thumb screw, Knurled



PO  
Pull handle - Multi-sector, Smooth hole



VQTplq  
Quarter-turn clamp lock - Clamping plate, Wall mounting



OP7  
Mechanical digital position indicator, 5 numbers

## Complementary products



CHAE6555  
Decorative screwed hinge, Aluminium



CHAM527055  
Marine hinge for welding/screw mounting, Marine