

★★★★ Stylish stainless steel screw hinge

CHAEss

316 stainless steel

- **Screw hinge**
- For right and left mounting
- 180° opening angle
- Fixed using countersunk screws (M5, M6 or M8 according to DIN 7991)
- The visible surface of the hinge has polished satin finish
- **Material:**
100% 316 stainless steel



Pin non-accessible

Impenetrable



Advantages

- Stylish visual appearance as the pin is not visible
- Vibration proof
- Vandal proof thanks to welds over the pin at both ends.

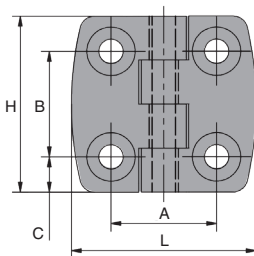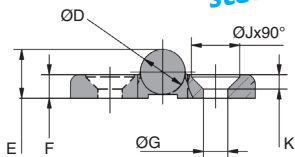

✓ IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	H	L	A	B	C	ØD	E	F	K	ØG	ØJ	Stock*	Price each 1 to 5
CHAE4042/SS	40	42	25	25	7,5	10,2	10,6	5	3,0	5,2	10,2	✓	30,86 €
CHAE5050/SS	50	50	30	30	10,0	12,0	12,5	6	3,7	6,2	12,4	✓	34,87 €
CHAE6063/SS	60	63	36	36	12,0	15,3	16,6	8	4,9	8,3	16,5	-	41,76 €

*Depending on availability - Dimensions in mm

Our other products




NT91
Spur gear coaxial gearbox, from 10 to 35 Nm - Inline



CCL55
Stainless steel wire thimble, Stainless steel



CLB_T
Die cast zinc clamping lever - male, Zamak

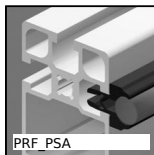

PRF_PSA
Shaft support for aluminium profile, Shaft support



PPJ
Indexing plunger with flange, With horizontal mounting flange and pu...



BPFL
Sheet steel flanged bearing for light loads, Sheet steel



PTAf80-PAMf80
Articulated fixable foot with pressed base Ø80, Ø 80



PCS50K
Chain sprocket with hardened teeth, 12.7mm (DIN08B-1)



DER90
Stainless steel AC asynchronous motor 1.1 - 1.5kW, 1.1 to



CHB
Worm and wheel gear reducer, up to 22 Nm



HLA28
Right angle spiro bevel gearbox, Up to 182Nm



ETQ
Magnetic label holder for aluminium profile, Label holder

Complementary products



CHAE3030PA
Square decorative screwed hinges, Polyamide



CHAE6555
Decorative screwed hinge, Aluminium



CHAEpac
Square decorative screwed hinges, carbon fibre reinforced



CHA1056_U4
Screw-in hinge, Section 40X40