

# ★★★★ Stylish stainless steel screw hinge

## CHAEss

## 316 stainless steel

- **Screw hinge**
- For right and left mounting
- 180° opening angle
- Fixed using countersunk screws (M5, M6 or M8 according to DIN 7991)
- The visible surface of the hinge has polished satin finish
- **Material:**  
100% 316 stainless steel



*Pin non-accessible*

**Impenetrable**



### Advantages

- Stylish visual appearance as the pin is not visible
- Vibration proof
- Vandal proof thanks to welds over the pin at both ends.

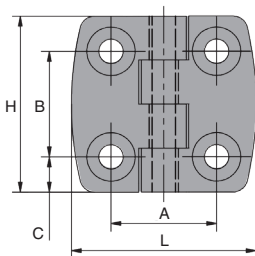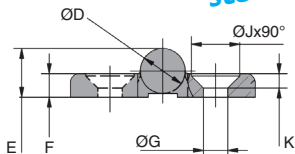

**✓ IN STOCK\***  
Otherwise contact us

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	H	L	A	B	C	ØD	E	F	K	ØG	ØJ	Stock*	Price each 1 to 5
CHAE4042/SS	40	42	25	25	7,5	10,2	10,6	5	3,0	5,2	10,2	✓	30,86 €
CHAE5050/SS	50	50	30	30	10,0	12,0	12,5	6	3,7	6,2	12,4	✓	34,87 €
CHAE6063/SS	60	63	36	36	12,0	15,3	16,6	8	4,9	8,3	16,5	-	41,76 €

\*Depending on availability - Dimensions in mm

**HPC** WEB 2017

www.hpceurope.com - Tel: +33(0)4 37 496 496

## Our other products



DBL821

Idler for slat top chain, Range 821



HW\_HT

Half-rail guide, Wheel



ACM\_DZ

Clip for bonnet fastener, Clip



H3

Crossed helical gear crossed axis at 90°, Steel 20NCD2



 
Q6

Deep groove ball bearing, Steel



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



IN1

Internal gear, Machined plastic (delrin)



RMSA

Adjustable shock-absorber, Adjustable



HS

Hexagonal spacer, Stainless steel 303



RHTplss

High Temperature Castor, up to 200kg



CLSCLP\_SS

Clevis components, short version, Stainless steel - short



EHD08-9

Internal epicyclic servo reducers, from 35 to 50 Nm

## Complementary products



CHAE3030PA

Square decorative screwed hinges, Polyamide



CHAE6555

Decorative screwed hinge, Aluminium



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced



CHA1056\_U4

Screw-in hinge, Section 40X40