

# ★★★★ Stylish stainless steel screw hinge

## CHAEss

## 316 stainless steel

- **Screw hinge**
- For right and left mounting
- 180° opening angle
- Fixed using countersunk screws (M5, M6 or M8 according to DIN 7991)
- The visible surface of the hinge has polished satin finish
- **Material:**  
100% 316 stainless steel



*Pin non-accessible*

**Impenetrable**



### Advantages

- Stylish visual appearance as the pin is not visible
- Vibration proof
- Vandal proof thanks to welds over the pin at both ends.

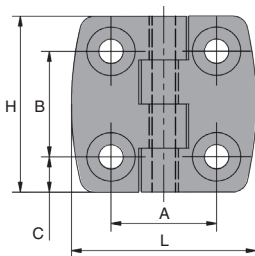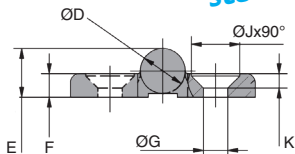

**✓ IN STOCK\***  
Otherwise contact us

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	H	L	A	B	C	ØD	E	F	K	ØG	ØJ	Stock*	Price each 1 to 5
CHAE4042/SS	40	42	25	25	7,5	10,2	10,6	5	3,0	5,2	10,2	✓	30,86 €
CHAE5050/SS	50	50	30	30	10,0	12,0	12,5	6	3,7	6,2	12,4	✓	34,87 €
CHAE6063/SS	60	63	36	36	12,0	15,3	16,6	8	4,9	8,3	16,5	-	41,76 €

\*Depending on availability - Dimensions in mm

**HPC** WEB  
2017

www.hpceurope.com - Tel: +33(0)4 37 496 496

## Our other products



NCT  
Square tube  
connector, Fixed  
angle



CDGamme  
Compression spring  
DIN2095, DIN 2095



B5M\_LOK  
Long-Lok spring  
plunger with internal  
hexagonal socket,  
LONG-LOK - s...



LWL  
Linear ball slide -  
Stainless steel balls,  
Rail - from 514 N to  
1670...



GE  
Toggle latches,  
Standard



ADL\_F  
Female eye bolt  
conforms to DIN582,  
Stainless steel



RPCtcss  
Swivel castor with  
central hole, Stainless  
steel - Polyamide -  
with ...



ZG0  
Plastic spur gear,  
Machined plastic  
(delrin)



NPTF20  
Spacer for tube  
carrier, Fixing  
accessory Ø10 to Ø14



BGC  
Oldham coupling,  
Clamp



PTRSS  
Idler chain sprocket,  
For hostile  
environments



UTKswc  
Utilitrak® 3 wheels  
carriage, Series V  
precision steel wheel

## Complementary products



CHAE3030PA  
Square decorative  
screwed hinges,  
Polyamide



CHAE6555  
Decorative screwed  
hinge, Aluminium



CHAEpac  
Square decorative  
screwed hinges,  
carbon fibre  
reinforced



CHA1056\_U4  
Screw-in hinge,  
Section 40X40