

# ★★★★ Stylish stainless steel screw hinge

## CHAEss

## 316 stainless steel

- **Screw hinge**
- For right and left mounting
- 180° opening angle
- Fixed using countersunk screws (M5, M6 or M8 according to DIN 7991)
- The visible surface of the hinge has polished satin finish
- Material:  
100% 316 stainless steel



*Pin non-accessible*

**Impenetrable**



### Advantages

- Stylish visual appearance as the pin is not visible
- Vibration proof
- Vandal proof thanks to welds over the pin at both ends.

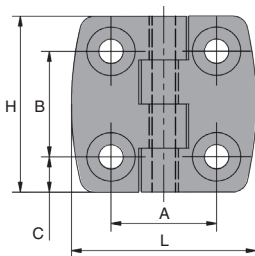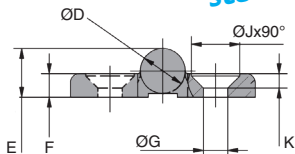

**✓ IN STOCK\***  
Otherwise contact us

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	H	L	A	B	C	ØD	E	F	K	ØG	ØJ	Stock*	Price each 1 to 5
CHAE4042/SS	40	42	25	25	7,5	10,2	10,6	5	3,0	5,2	10,2	✓	30,86 €
CHAE5050/SS	50	50	30	30	10,0	12,0	12,5	6	3,7	6,2	12,4	✓	34,87 €
CHAE6063/SS	60	63	36	36	12,0	15,3	16,6	8	4,9	8,3	16,5	-	41,76 €

\*Depending on availability - Dimensions in mm

**HPC** WEB 2017

www.hpceurope.com - Tel: +33(0)4 37 496 496

## Our other products



HCSS

Set screw with hexagonal socket, Cup point



QN

Single row cylindrical roller bearing, Free outer ring



E40

Right angle helical reducers, from 2.30 to 20 Nm



CHMR50

Worm and wheel gear reducer, up to 107 Nm



RHTtcss

High Temperature Castor, up to 200kg



PR40

Articulated foot Ø40, Ø 40



VLBG

Lifting ring, Rotating



PM4

Worm and wheel set, Machined plastic (delrin)




TB8

Cylindrical roller thrust bearing, Steel



BPQ

 Quadro linear ball bearing unit, Included 4 linear ball bearings



LAT1

1A motorised linear actuator, 1 ampere



PTA50ssEB

Articulated foot with sheet metal base Ø50, Articulated foot

## Complementary products



CHAE3030PA

Square decorative screwed hinges, Polyamide



CHAE6555

Decorative screwed hinge, Aluminium



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced



CHA1056\_U4

Screw-in hinge, Section 40X40