

# Stylish stainless steel screw hinge

## CHAESS

## 316 stainless steel



- Screw hinge
- For right and left mounting
- 180° opening angle
- Fixed using countersunk screws (M5, M6 or M8 according to DIN 7991)
- The visible surface of the hinge has polished satin finish
- Material:  
100% 316 stainless steel

### Advantages

- Stylish visual appearance as the pin is not visible
- Vibration proof
- Vandal proof thanks to welds over the pin at both ends.

*Pin non-accessible*

**Impenetrable**

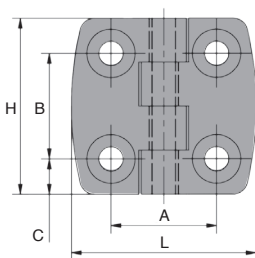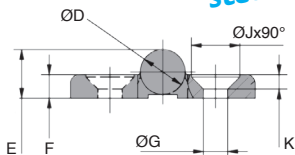

### DISCOUNTS

| Qty   | 1+   | 6+  | 20+  | 50+        |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | H  | L  | A  | B  | C    | ØD   | E    | F | K   | ØG  | ØJ   | Stock* | Price each<br>1 to 5 |
|-------------|----|----|----|----|------|------|------|---|-----|-----|------|--------|----------------------|
| CHAE4042/SS | 40 | 42 | 25 | 25 | 7,5  | 10,2 | 10,6 | 5 | 3,0 | 5,2 | 10,2 | ✓      | 30,86 €              |
| CHAE5050/SS | 50 | 50 | 30 | 30 | 10,0 | 12,0 | 12,5 | 6 | 3,7 | 6,2 | 12,4 | ✓      | 34,87 €              |
| CHAE6063/SS | 60 | 63 | 36 | 36 | 12,0 | 15,3 | 16,6 | 8 | 4,9 | 8,3 | 16,5 | -      | 41,75 €              |

All dimensions in mm

## Our other products



ZG1

Spur gear, Machined plastic (delrin)



BPLE

Ball transfer unit, Light



NJM

Adjustable cross clamp, Multiple



CHM63

Worm and wheel gearbox, up to 196 Nm



ACLAPA

Closing system, Magnetic stop



DKN

Bellows coupling Gerwah®, from 0.4 to 10Nm



UGH40

H Type Guide units, For Ø40 actuators



BFDdII

Locking pin for bushes, Nickel-plated steel



D19\_D29

Compression spring, by the metre



CDR

Ball pin, Retaining cable



LRR-53

Latch, Spring return latch - steel



PF20

Worm and wheel gearbox, up to 5 Nm

## Complementary products



CHAE3030PA

Decorative hinges, Polyamide



CHAE6555

Decorative hinges, Aluminium



CHA1056\_U8

Screw-in hinge, Section 50X50



CHA1056\_U12

Screw-in hinge, Section 60X60