

# Miniature friction hinge

Faille  
**XS**




## CHAFRMINI

POM black or white

- Screw-on front hinge
- Opening angle 270°
- Materials:
  - White or black acetal
  - 304 stainless steel pin
- Tested for 20,000 open/close cycles

### Advantage

- Miniature hinge, space saving
- Hold a door in position thanks to its self-locking system

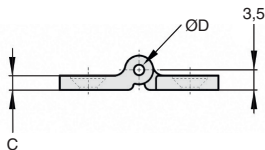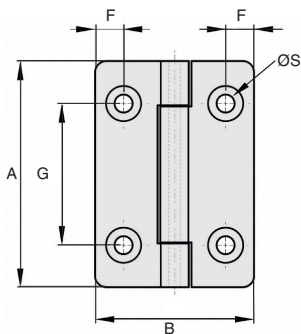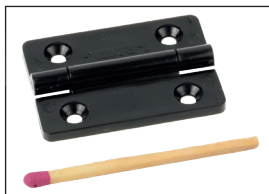

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Net	-5%	-10%	On request

Part N°	Colour	A	B	C	ØD	F	G	ØS	Friction torque (Nm)	Weight (g)	Stock*	Price each
CHAFR4028/MIN/B	Noir	40	28	2,5	2	5	25	3,2	0,25	5	-	10,82 €
CHAFR4028/MIN/W	Blanc	40	28	2,5	2	5	25	3,2	0,25	5	-	10,82 €

All dimensions in mm

## Our other products



PTAF80-PAMF80  
Articulated fixable  
foot with pressed  
base Ø80, Ø 80



RDERSS  
Stainless steel manual  
rigging screw,  
Stainless steel -  
manual



PSG1  
Spur gear - precision  
range, Case hardened  
steel 20NCD2



RT61ss  
Self-centering locking  
Assembly,  
Medium/low torque



VCMB  
Dual-thread screw  
wood/metal, Steel



Q6  
Deep groove ball  
bearing, Steel



NKIA  
Combined bearing  
with inner ring, Axial  
load in one direction



HS  
Hexagonal spacer,  
Stainless steel 303



DOMI50  
Accessories, Turntable



BPFss  
Pressed stainless  
steel flange bearing,  
Stainless steel



PRF\_FIX\_STD  
Fastener for  
aluminium profile,  
Standard fastener



PCLA\_T  
Technopolymer  
clamping lever - male,  
Plastic

## Complementary products



CHAFR-MINI  
Miniature friction  
hinge, Friction



CHAFR  
Adjustable friction  
hinges, Friction