

Adjustable friction hinges

Stock



 

CHAFR

For opening and positioning a panel or door

- Screw-on front hinge
- Materials :
 - Aluminium
 - Sleeve : POM
 - Adjustable screw : Stainless steel A2
- Plain or black anodised finish
- Holding force : 0 to 5 Nm max
- Adjusts using 4mm Allen key
- Withstands 6000N
- Shear force : 5000N
- Working temp range -20 to 80°C

Advantages

- Adjustable holding force
- Aesthetic hinge

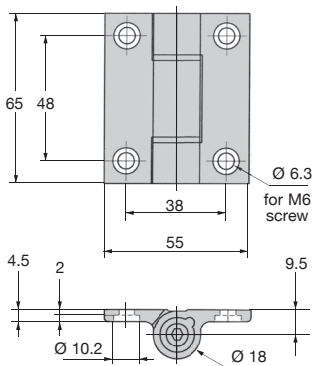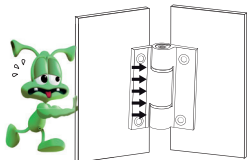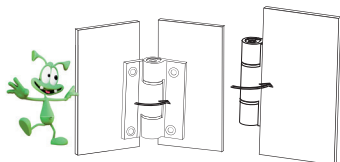

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	


Part number	Finish	Stock*	Price each 1 to 5
CHAFR6555/AI	Plain anodised	✓	25,59 €
CHAFR6555/AN	Black anodised	✓	25,59 €

*Depending on availability - Dimensions in mm

Our other products



 DOMI_MD
Domino rotary table,
40/1



ACLBTS
Closing system for
aluminium profile, 90°
bracket for spherical
end...



GB-RA
Brass spur gear, Brass
CuZn39Pb3



UGH20
H Type Guide units,
For Ø20 actuators



AFM
Flanged polymer
bush, Food grade
polymer




BOX-WM
Box set of washer -
DIN125, Box set of
steel washers



ABL100000
Antistatic brush, For
sensitive surfaces



 AK
Bellows coupling
Gerwah®, from 36 to
800Nm



RPPM
RPP type belt per
metre, RPP14 Steel
cored polyurethane



V3RA
3-spoked handwheel
without handle,
Polyamide



BABS
630 Stainless steel
compact ball pin,
Hardened stainless



TBD
Manual leadscrew
table with opposing
threads, 2kg

Complementary products



CHAR5050_Z
Spring hinge, screwed



CHAC4040SS
Square hinge with
riveted pin, drilled,
Square with riveted
pin, dri...



CHAFR-MINI
Miniature friction
hinge, Friction



CHAFR-MINI
Miniature friction
hinge, Friction