

# Adjustable friction hinges

Stock



 

## CHAFR

For opening and positioning a panel or door

- Screw-on front hinge
- Materials :
  - Aluminium
  - Sleeve : POM
  - Adjustable screw : Stainless steel A2
- Plain or black anodised finish
- Holding force : 0 to 5 Nm max
- Adjusts using 4mm Allen key
- Withstands 6000N
- Shear force : 5000N
- Working temp range -20 to 80°C

### Advantages

- Adjustable holding force
- Aesthetic hinge

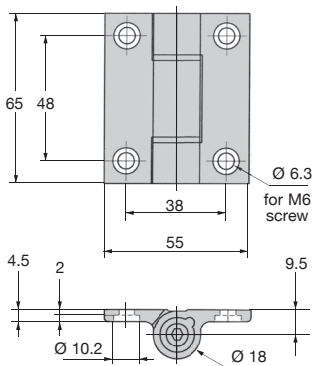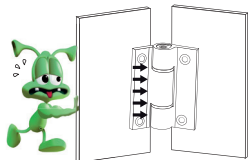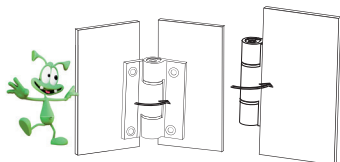

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

 
Part number	Finish	Stock*	Price each 1 to 5
CHAFR6555/AI	Plain anodised	✓	25,59 €
CHAFR6555/AN	Black anodised	✓	25,59 €

\*Depending on availability - Dimensions in mm

## Our other products



SCH  
Horizontal hook  
toggle clamp,  
Horizontal Hook  
clamp - steel




PRL  
Wear strip for slat top  
chain, L profile to be  
clipped



BIM  
Indexing plunger mini,  
miniature



 
CHAuss  
Screwed hinge, 270°



PRF\_CHA D  
Hinge and joint, Lift-  
off hinge



 AC  
Strike for toggle latch,  
15mm



ACL-PR  
Joining plate for  
aluminium profile,  
Right angled  
connection



ZB  
Shaft for linear  
guides, Hardened  
ground stainless steel



PM2  
Worm and wheel set,  
Hardened steel



MBF  
Threaded blocking  
clamp, Threaded



PRF\_PSA  
Shaft support for  
aluminium profile,



CQA20  
Adjustment slide-  
system miniature, 20

## Complementary products



CHAR5050\_Z  
Spring hinge, screwed



CHAC4040SS  
Square hinge with  
riveted pin, drilled,  
Square with riveted  
pin, dri...



CHAFR-MINI  
Miniature friction  
hinge, Friction



CHAFR-MINI  
Miniature friction  
hinge, Friction