

Miniature friction hinge

Faille
XS




CHAFRMINI

POM black or white

- Screw-on front hinge
- Opening angle 270°
- Materials:
 - White or black acetal
 - 304 stainless steel pin
- Tested for 20,000 open/close cycles

Advantage

- Miniature hinge, space saving
- Hold a door in position thanks to its self-locking system

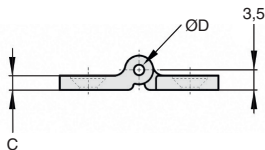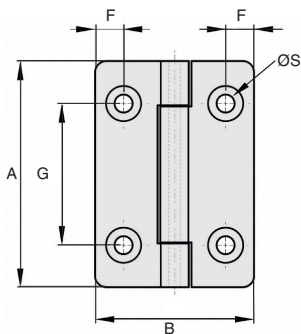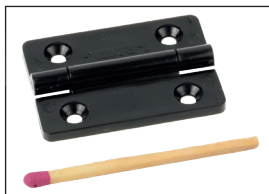


DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Net	-5%	-10%	On request

Part N°	Colour	A	B	C	ØD	F	G	ØS	Friction torque (Nm)	Weight (g)	Stock*	Price each
CHAFR4028/MIN/B	Noir	40	28	2,5	2	5	25	3,2	0,25	5	-	10,82 €
CHAFR4028/MIN/W	Blanc	40	28	2,5	2	5	25	3,2	0,25	5	-	10,82 €

All dimensions in mm

 Our other products



EPRF

High helix leadscrew,
Flanged nut - up to
40mm per rotation



PR40

Articulated foot Ø40,
Ø 40



PGT

Sliding profile, Sliding
panel support



PSG08

Spur gear - precision
range, Case hardened
steel 20NCD2



DBL821

Idler for slat top
chain, Range 821



MPS

Hexagonal spacer,
Stainless steel 303



CHA35

Hinge for aluminium
profile, Hinge



HW_HT

Half-rail guide, Rail
profile



PTKFss

Cap nut for foot for
the food industry,



RIMple

Locking castor, with
mounting plate



BH02

Single housed bearing
assembly, Bearing



HG6

Steel spur gear, Steel
20NCD2

Complementary products



CHAFR-MINI

Miniature friction
hinge, Miniature
friction hinge



CHAFR

Adjustable friction
hinges, Adjustable
friction