

Adjustable friction hinges

Stock



 

CHAFR

For opening and positioning a panel or door

- Screw-on front hinge
- Materials :
 - Aluminium
 - Sleeve : POM
 - Adjustable screw : Stainless steel A2
- Plain or black anodised finish
- Holding force : 0 to 5 Nm max
- Adjusts using 4mm Allen key
- Withstands 6000N
- Shear force : 5000N
- Working temp range -20 to 80°C

Advantages

- Adjustable holding force
- Aesthetic hinge

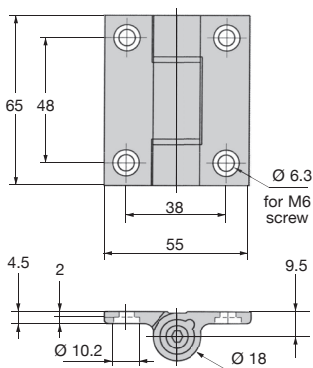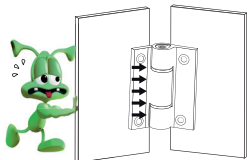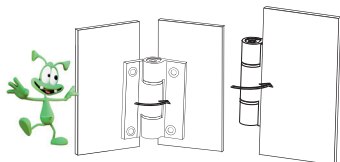

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Finish	Stock*	Price each 1 to 5
CHAFR6555/AI	Plain anodised	✓	25,59 €
CHAFR6555/AN	Black anodised	✓	25,59 €

 
*Depending on availability - Dimensions in mm

Our other products




ACL-PL

Joining plate for aluminium profile, Joint plate - 86x86 mm



T5courroie

 T type timing belt, T5 Steel cored polyurethane



PRZ

Wear strip for slat top chain, Z profile to be filled



 
CLSCLP

Clevis components, short version, Steel - short range



SSG1_304L

Stainless steel spur gear, Stainless steel 304L



RPP8

RPP heavy duty timing belt, RPP8



RURt

Swivel castor with central hole, Polyurethane - Aluminium rim (Free



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel



TIFss

Threaded stud - DIN976A, Stainless steel



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



DH

Dowel pin, Solid DIN 6325



UCFL_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel

Complementary products



CHAR5050_Z

Spring hinge, screwed



CHAC4040SS

Square hinge with riveted pin, drilled, Square with riveted pin, dri...



CHAFR-MINI

Miniature friction hinge, Friction



CHAFR-MINI

Miniature friction hinge, Friction