

# Adjustable friction hinges

Stock



 

## CHAFR

For opening and positioning a panel or door

- Screw-on front hinge
- Materials :
  - Aluminium
  - Sleeve : POM
  - Adjustable screw : Stainless steel A2
- Plain or black anodised finish
- Holding force : 0 to 5 Nm max
- Adjusts using 4mm Allen key
- Withstands 6000N
- Shear force : 5000N
- Working temp range -20 to 80°C

### Advantages

- Adjustable holding force
- Aesthetic hinge

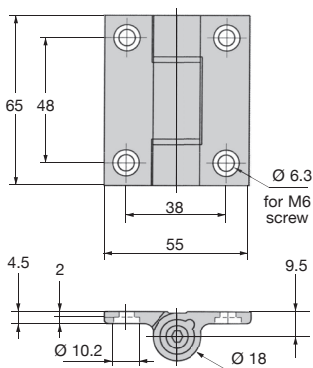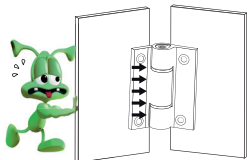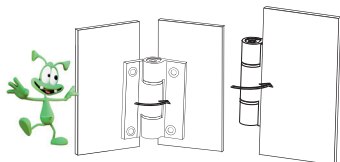

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Finish	Stock*	Price each 1 to 5
CHAFR6555/AI	Plain anodised	✓	25,59 €
CHAFR6555/AN	Black anodised	✓	25,59 €

\*Depending on availability - Dimensions in mm

## Our other products



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



CHM75

Worm and wheel gear reducer, up to 298 Nm



V3RA

3-spoked handwheel without handle, Polyamide



BPTR

End cap for round tube, Standard



PT820

Drive sprocket for slat top chain, Ranges 820 and 815




PLM-SC

Magnetic stud with central countersunk hole, With milled bore



LC

Friction clutch, 190 to 1800 Nm

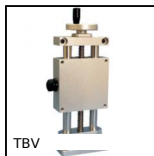

TBV

Manual lifting tables, For vertical strokes - Ø 25 mm column



ASH

Hoist ring for welding, for straight lifts - for



PRF3232

Standard aluminium profile, 32 x 32 mm



CHAC4040SS

Square hinge with riveted pin, drilled,



ABL100005

Antistatic brush, Standard

## Complementary products



CHAR5050\_Z

Spring hinge for screw mounting, screwed



CHAC4040SS

Square hinge with riveted pin, drilled, Square with riveted pin, dri...



CHAFR-MINI

Miniature friction hinge, Miniature friction hinge



CHAFR-MINI

Miniature friction hinge, Miniature friction hinge