

- Screw-on hinge
- Opening angle 270°
- Materials:
 - Aluminium 6060 T5
 - Stainless steel spindle
 - Plastic caps

Advantage


- Reduced space requirement
- Lift-off




Clear anodised




Black anodised

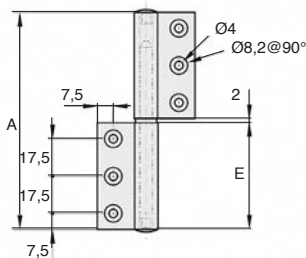

Type 1

 

Type 2

 

DISCOUNTS

Qty	1+	6+	20+	50+
Disc	Net	-5%	-10%	On request

Part N°	Type	Finish	A	B	C	ØD	E	Weight (g)	Price each
									1 à 5
CHA-GC-9-1/AL/IN	1	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/IN	2	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-1/AL/BK	1	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/BK	2	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €

All dimensions in mm

 
0 825 88 6000

Service 0,15 € / min
+ prix appel

Our other products



UGAC_UGET
Actuator guide kit,
Coupling for threaded
cylinder end



BCM_HPBT
Modular cylindrical
brush, PBT polyester
bristles



NPTF30
Spacer for tube
carrier, Fixing
accessory Ø14 to Ø20



CHMR50
Worm and wheel gear
reducer, up to 107
Nm



BABreceptacle
Ball pin socket, Socket



BZY_SS
Stainless steel
cylindrical elastomeric
mount, Stainless steel



GCH
Linear ball slide -
Stainless steel balls,
Chariot - from 514 N
to 1...



BLHT40
Right angled gearbox,
from 4 to 10.30 Nm



WJUM10
Drylin® W bearing
block, Slide



PTRSS
Idler chain sprocket,
For hostile
environments



VELprf
Clip-on base for hook-
and-loop strip,
Polyamide



CSS
Spherical bushing,
Steel / self-lubricating
steel

Complementary products



CHA_GC_9SS
Stainless steel garnet
hinge, To be welded



CHA_GC_9SS
Stainless steel garnet
hinge, To be welded



CHAGC-AL
Screw-in garnet
hinge, Screw-on