

- Screw-on hinge
- Opening angle 270°
- Materials:
 - Aluminium 6060 T5
 - Stainless steel spindle
 - Plastic caps

Advantage


- Reduced space requirement
- Lift-off




Clear anodised




Black anodised

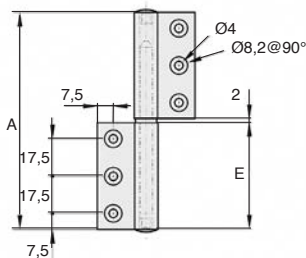

Type 1

 

Type 2

 

DISCOUNTS

Qty	1+	6+	20+	50+
Disc	Net	-5%	-10%	On request

Part N°	Type	Finish	A	B	C	ØD	E	Weight (g)	Price each
									1 à 5
CHA-GC-9-1/AL/IN	1	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/IN	2	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-1/AL/BK	1	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/BK	2	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Our other products



 
PGNT

Thermoplastic T handle, With threaded insert



T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



BETA

Hitch pin, Hitch



BAN

Angular clamp, Standard



CHA225

Screwed hinge with threaded insert, 225 degrees



VTHA

Magnetic screw with hexagonal head, Steel



PR882

Idler sprocket for slat top chain, Range 882



AC

Strike for toggle latch, 15mm



SHA_PT

Handwheel with handle, Polyamide



AC144

Strike for toggle latch, 22mm



FB_ECO

Eco. range steel bevel gear, 4:1



PLM-20SC

Threaded cylindrical magnet, With threaded hole

Complementary products



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHAGC-AL

Screw-in garnet hinge, Screw-on



CHA_GC_14SS

Stainless steel garnet hinge, To screw