

- Screw-on hinge
- Opening angle 270°
- Materials:
 - Aluminium 6060 T5
 - Stainless steel spindle
 - Plastic caps

Advantage


- Reduced space requirement
- Lift-off




Clear anodised




Black anodised

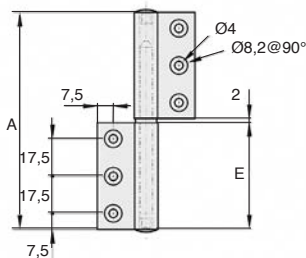

Type 1

 

Type 2

 

DISCOUNTS

Qty	1+	6+	20+	50+
Disc	Net	-5%	-10%	On request

Part N°	Type	Finish	A	B	C	ØD	E	Weight (g)	Price each
									1 à 5
CHA-GC-9-1/AL/IN	1	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/IN	2	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-1/AL/BK	1	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/BK	2	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Our other products



EML

Stainless steel hexagonal headed thumb nut, Lobed handscrew



FBL6000_K13

Brush strip per meter PP fibres Ø0.2, Black striated polypropylene ...



DB

Steel bevel gear, 2:1



F7-I

Multifunction display, With internal sensor



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Micromet...



LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread



BAC110

Swivel storage bin, Storage bin



SSG2_304L

Stainless steel spur gear, Stainless steel 304L



PM3

Worm and wheel set, Hardened steel



WJUM20

Drylin® W bearing block, Slide



T25-6ECO

T type timing pulley, Economy range - T2.5 aluminium



AT5M_AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane

Complementary products



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHAGC-AL

Screw-in garnet hinge, Screw-on



CHA_GC_14SS

Stainless steel garnet hinge, To screw