

- Screw-on hinge
- Opening angle 270°
- Materials:
 - Aluminium 6060 T5
 - Stainless steel spindle
 - Plastic caps

Advantage


- Reduced space requirement
- Lift-off




Clear anodised




Black anodised

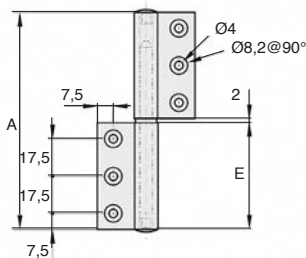

Type 1

 

Type 2

 

DISCOUNTS

Qty	1+	6+	20+	50+
Disc	Net	-5%	-10%	On request

Part N°	Type	Finish	A	B	C	ØD	E	Weight	Price each
								(g)	1 à 5
CHA-GC-9-1/AL/IN	1	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/IN	2	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-1/AL/BK	1	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/BK	2	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Our other products



PTA80

Articulated levelling foot, pressed base
Ø80, Ø 80



ZBconique

Machined plastic bevel gear , 1:1



H025S

Needle roller universal joint - Stainless steel,
Heavy duty
DIN808-7...



BABT

Hardened Stainless steel ball pin,
Hardened stainless steel



PRF_PF

Anchoring bracket for aluminium profile,
Anchor



PSG15S

Spur gear - precision range, Stainless steel
303



SLB

Indexing plunger,
steel class 5.8



GPB5S

Threaded spherical knob, Stainless steel
304



PRF1932

Standard aluminium profile, 19 x 32 mm



E20

Right angle helical reducers, from 0.60 to



PRF_CLIP_45

Cable clip for aluminium profile, For



RAM35

Manual bevel gearbox, Bevel

Complementary products



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHAGC-AL

Screw-in garnet hinge, Screw-on



CHA_GC_14SS

Stainless steel garnet hinge, To screw