

- Screw-on hinge
- Opening angle 270°
- Materials:
  - Aluminium 6060 T5
  - Stainless steel spindle
  - Plastic caps

**Advantage**


- Reduced space requirement
- Lift-off




Clear anodised




Black anodised

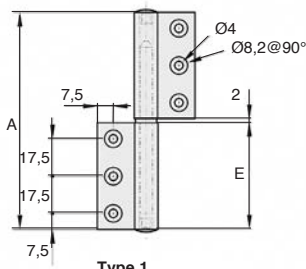

Type 1

 

Type 2

 **DISCOUNTS**

Qty	1+	6+	20+	50+
Disc	Net	-5%	-10%	On request

Part N°	Type	Finish	A	B	C	ØD	E	Weight (g)	Price each
									1 à 5
CHA-GC-9-1/AL/IN	1	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/IN	2	Clear anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-1/AL/BK	1	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €
CHA-GC-9-2/AL/BK	2	Black anodised	102	45,9	2,5	6,1	50	50	17,14 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min  
+ prix appel

## Our other products



PPS

Lifting ring, Universal threaded



PBG

PRECISION range (Quality Grade 7f24), 1:1



NDS20

Double cross clamp, Parallel



PRF\_GAL

Roller for aluminium profile, Fixing kit for roller eccentric



PW\_PWG3

Wheel - precision range, Bronze



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



BLHB40

Right angled gearbox, bored shafts, up to 10.3 Nm



INO

Internal gear, Machined plastic (delrin)



BL15

Right angled gearbox, from 1.10 to 6 Nm



NSP

Right angled support clamp, Right angled support clamp



BRI

Panel holder, Panel holder



PSG35

Spur gear - precision range, Stainless steel 303

## Complementary products



CHA\_GC\_9SS

Stainless steel garnet hinge, To be welded



CHA\_GC\_9SS

Stainless steel garnet hinge, To be welded



CHAGC-AL

Screw-in garnet hinge, Screw-on