

Long hinge in steel or aluminium **AluSte**

CHAL

Piano type hinge

- Long hing with a small pin diameter
- Rolled joint
- Hinge is not drilled
- Materials:
 - Untreated steel
 - Aluminium

Economical





Applications

- Woodworking, industrial joinery, workstations...

Advantages

- Compact design
- Possibility of cutting to the length desired

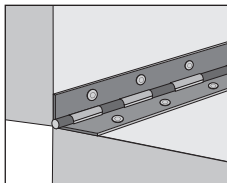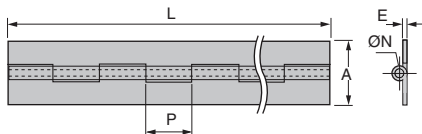

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	A	L	P	E	ØN	Weight per metre (kg/m)	Price each 1 to 5
Steel							
CHAL3-40-1000	40	1000	20	1,2	3	0,530	12,33 €
CHAL3-50-1000	50	1000	20	1,2	3	0,610	12,98 €
Aluminium							
CHAL3-35-1000/A	35	1000	20	1,0	3	0,175	14,37 €
CHAL3-40-1000/A	40	1000	20	1,0	3	0,208	14,56 €
CHAL4-50-1000/A	50	1000	30	1,5	4	0,300	18,95 €

Dimensions in mm

- Long hinge with a small pin diameter
- Rolled joint
- Hinge is not drilled
- Material:
304 stainless steel

Economical





Applications

- Woodworking, industrial joinery, workstations...

Advantages

- Compact design
- Possibility of cutting to the length desired

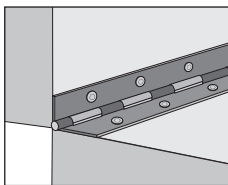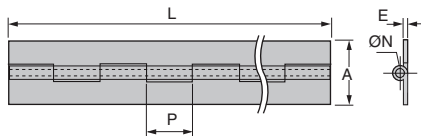

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	A	L	P	E	ØN	Weight per metre (kg/m)	Stock*	Price each 1 to 5
CHAL2-20-1000/SS	20	1000	15	0,6	2,5	0,140	✓	17,09 €
CHAL2-25-1000/SS	25	1000	15	0,6	2,5	0,165	-	17,11 €
CHAL2-30-1000/SS	30	1000	15	0,6	2,5	0,190	-	18,10 €
CHAL3-25-1000/SS	25	1000	20	1,0	3,0	0,325	✓	18,26 €
CHAL3-40-1000/SS	40	1000	20	1,2	3,0	0,520	✓	24,88 €
CHAL3-50-1000/SS	50	1000	20	1,2	3,0	0,620	✓	26,87 €
CHAL6-60-1000/SS	60	1000	30	2,0	6,0	1,470	✓	66,33 €
CHAL6-80-1000/SS	80	1000	30	2,0	6,0	1,700	-	75,93 €

Dimensions in mm

Our other products



BC3
Panamech, Multi-Beam stainless steel, Stainless steel - with clampin...



FF30
Offset spur gear reducer, from 21.50 to 83 Nm



GAL_20
Conveyor roller for Ø20mm spindle, Self-lubricating polyamide



GLB
Small 6 lobe female handle, Technopolymer - Brass



DOMI30
Connecting kits, XY linking kit



BLHB20
Right angled gearbox, bored shafts, up to 1.77 Nm



SH1
Parallel axis helical gear, Steel 20NCD2



LFM2
Steel leadscrew, Medium carbon steel - 2 threads



SCH
Horizontal hook toggle clamp, Horizontal Hook



PCLA_M
Technopolymer clamping lever - female, Plastic



SH4
Parallel axis helical gear, Steel 20NCD2



UGAC_UGET
Actuator guide kit, Coupling for threaded cylinder end

Complementary products



CHAL3
Piano hinge, Aluminium



CHALss
Piano hinge, Stainless steel