

# Long hinge in steel or aluminium **AluSte**

## CHAL

## Piano type hinge

- Long hing with a small pin diameter
- Rolled joint
- Hinge is not drilled
- Materials:
  - Untreated steel
  - Aluminium

**Economical**





### Applications

- Woodworking, industrial joinery, workstations...

### Advantages

- Compact design
- Possibility of cutting to the length desired

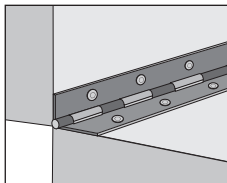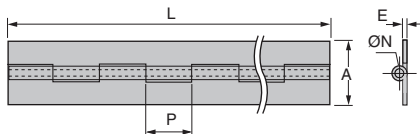

Typical application

### DISCOUNTS

Qty	1+	6+	20+
Disc. List		-5%	On request

Part number	A	L	P	E	ØN	Weight per metre (kg/m)	Stock*	Price each 1 to 5
<b>Steel</b>								
CHAL3-40-1000	40	1000	20	1,2	3	0,530	✓	12,33 €
CHAL3-50-1000	50	1000	20	1,2	3	0,610	✓	12,98 €
<b>Aluminium</b>								
CHAL3-35-1000/A	35	1000	20	1,0	3	0,175	✓	14,37 €
CHAL3-40-1000/A	40	1000	20	1,0	3	0,208	✓	14,56 €
CHAL4-50-1000/A	50	1000	30	1,5	4	0,300	✓	18,95 €

\*Depending on availability - Dimensions in mm

- Long hinge with a small pin diameter
- Rolled joint
- Hinge is not drilled
- Material:  
304 stainless steel

Economical





### Applications

- Woodworking, industrial joinery, workstations...

### Advantages

- Compact design
- Possibility of cutting to the length desired

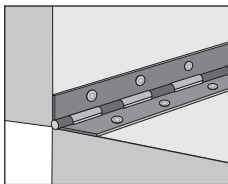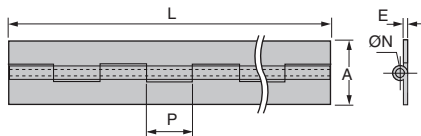

Typical application

### DISCOUNTS

Qty	1+	6+	20+
Disc. List	-5%	On request	

Part number	A	L	P	E	ØN	Weight per metre (kg/m)	Stock*	Price each 1 to 5
CHAL2-20-1000/SS	20	1000	15	0,6	2,5	0,140	✓	17,09 €
CHAL2-25-1000/SS	25	1000	15	0,6	2,5	0,165	-	17,11 €
CHAL2-30-1000/SS	30	1000	15	0,6	2,5	0,190	-	18,10 €
CHAL3-25-1000/SS	25	1000	20	1,0	3,0	0,325	✓	18,26 €
CHAL3-40-1000/SS	40	1000	20	1,2	3,0	0,520	✓	24,88 €
CHAL3-50-1000/SS	50	1000	20	1,2	3,0	0,620	✓	26,87 €
CHAL6-60-1000/SS	60	1000	30	2,0	6,0	1,470	✓	66,33 €
CHAL6-80-1000/SS	80	1000	30	2,0	6,0	1,700	-	75,93 €

\*Depending on availability - Dimensions in mm

## Our other products



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



BAN

Angular clamp, Adjustable



VTHbr

Hexagonal headed screw VTH - DIN933, Brass



ETP

Modular handle for aluminium profile, Modular handle



LRM2

Cylindrical bronze nut, Bronze - 2 threads



PSG35

Spur gear - precision range, Stainless steel 316



WJRM

Drylin® W hybrid bearing block, Hybrid bearings



AT5-BAR

AT type tooth bar stock, AT5



CHMR40

Worm and wheel gear reducer, up to 57 Nm



RJA00\_02

Sealing strip, Clipping



PW\_PWG25

Worm - precision range, Stainless steel



TBbutee

Axial thrust bearing, Steel balls

## Complementary products



CHAL3

Piano hinge, Steel