

Long hinge in steel or aluminium **AluSte**

CHAL

Piano type hinge

- Long hing with a small pin diameter
- Rolled joint
- Hinge is not drilled
- Materials:
 - Untreated steel
 - Aluminium

Economical





Applications

- Woodworking, industrial joinery, workstations...

Advantages

- Compact design
- Possibility of cutting to the length desired

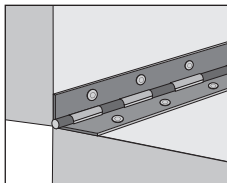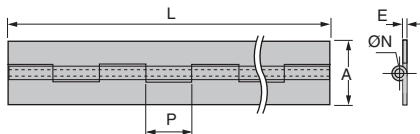

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc. List		-5%	On request

Part number	A	L	P	E	ØN	Weight per metre (kg/m)	Stock*	Price each 1 to 5
Steel								
CHAL3-40-1000	40	1000	20	1,2	3	0,530	✓	12,33 €
CHAL3-50-1000	50	1000	20	1,2	3	0,610	✓	12,98 €
Aluminium								
CHAL3-35-1000/A	35	1000	20	1,0	3	0,175	✓	14,37 €
CHAL3-40-1000/A	40	1000	20	1,0	3	0,208	✓	14,56 €
CHAL4-50-1000/A	50	1000	30	1,5	4	0,300	✓	18,95 €

*Depending on availability - Dimensions in mm

- Long hinge with a small pin diameter
- Rolled joint
- Hinge is not drilled
- Material:
304 stainless steel

Economical





Applications

- Woodworking, industrial joinery, workstations...

Advantages

- Compact design
- Possibility of cutting to the length desired

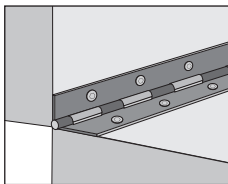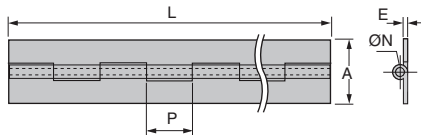

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc. List	-5%	On request	

Part number	A	L	P	E	ØN	Weight per metre (kg/m)	Stock*	Price each 1 to 5
CHAL2-20-1000/SS	20	1000	15	0,6	2,5	0,140	✓	17,09 €
CHAL2-25-1000/SS	25	1000	15	0,6	2,5	0,165	-	17,11 €
CHAL2-30-1000/SS	30	1000	15	0,6	2,5	0,190	-	18,10 €
CHAL3-25-1000/SS	25	1000	20	1,0	3,0	0,325	✓	18,26 €
CHAL3-40-1000/SS	40	1000	20	1,2	3,0	0,520	✓	24,88 €
CHAL3-50-1000/SS	50	1000	20	1,2	3,0	0,620	✓	26,87 €
CHAL6-60-1000/SS	60	1000	30	2,0	6,0	1,470	✓	66,33 €
CHAL6-80-1000/SS	80	1000	30	2,0	6,0	1,700	-	75,93 €

*Depending on availability - Dimensions in mm

Our other products



AC156-157

Strike for toggle latch,
25.5mm



DOMI80

Connecting kits, XZ
linking kit



PSG25

Spur gear - precision
range, Pre-hardened
Steel 35NCD6



GAL_20

Conveyor roller for
Ø20mm spindle, Self-
lubricating polyamide



BSB

Ballscrew bearing
unit, Support



PTAF100-PAMF100

Articulated fixable
foot with pressed
base Ø100, Ø 100



PTA150

Articulated levelling
foot, pressed base
Ø150, Ø 150



RAS

90° ball and socket
joints DIN71802, Steel



SH0

Parallel axis helical
gear, Steel 20NCD2



PPG

Indexing plunger with
flange, With
horizontal mounting



G0

Steel spur gear, Steel
20NCD2



PDR-RD

Mounting feet with
integrated castors,
Offset castor

Complementary products



CHAL3

Piano hinge, Steel