
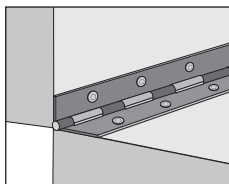


- Long hinge with a small pin diameter
- Rolled joint
- Hinge is not drilled
- Material:  
304 stainless steel

### Applications

- Woodworking, industrial joinery, workstations...

Economical

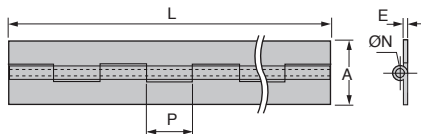

Typical application

### DISCOUNTS

 
Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	A	L	P	E	ØN	Stock*	Weight per metre (kg/m)	Price each 1 to 5
CHAL2-20-1000/SS	20	1000	15	0,6	2,5	✓	0,140	16,61 €
CHAL2-25-1000/SS	25	1000	15	0,6	2,5	-	0,165	16,63 €
CHAL2-30-1000/SS	30	1000	15	0,6	2,5	-	0,190	17,59 €
CHAL3-25-1000/SS	25	1000	20	1,0	3,0	-	0,325	17,75 €
CHAL3-40-1000/SS	40	1000	20	1,2	3,0	✓	0,520	24,18 €
CHAL3-50-1000/SS	50	1000	20	1,2	3,0	✓	0,620	26,11 €
CHAL6-60-1000/SS	60	1000	30	2,0	6,0	✓	1,470	64,46 €
CHAL6-80-1000/SS	80	1000	30	2,0	6,0	-	1,700	73,78 €

All dimensions in mm

Fax **0 825 88 6000**  
Service 0,15 €/min  
+ prix appel

## Our other products




PRF-SCREEN-5

Screen support,  
Support with 5 axes of  
rotation



CLASS

 Clamping lever -  
female, Stainless steel



NK80

Drylin® N miniature  
guidance, Width  
80mm



BABreceptacle

Ball pin, Socket



PLM-C

Magnetic stud,  
Cylindrical holding  
magnet



BHEX

Hexagonal cap, Black  
technopolymer



SH1

Parallel axis helical  
gear, Machined plastic  
(delrin)



MPE

Spacer, Steel



VLBS

Lifting ring, Folding -  
for welding



GG2

Ground spur gear,  
Heat treated steel



AC144

Catch plate for toggle  
latch, 22mm



CLG2

Spur gear, Moulded  
plastic (nylon)

## Complementary products



CHAL

Piano hinge,  
Aluminium



CHAL3

Piano hinge, Steel