

CHARCAV

Very easy to install

- Spring-loaded hinges with stopper to lock the hinges in the open position for easy assembly

- 270° opening angle

- Material

304 stainless steel, stainless steel spring

- Spring torque

Opening spring:

M(0°): 1.6 Nm

M(90°): 1.2 Nm

M(180°): 0.84 Nm

Closing spring:

 



M(0°): 0.75 Nm

M(90°): 1.2 Nm

M(180°): 1.65 Nm

Info

- Spring hinge opens or closes delivered flat

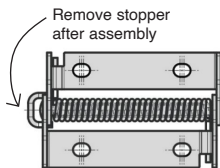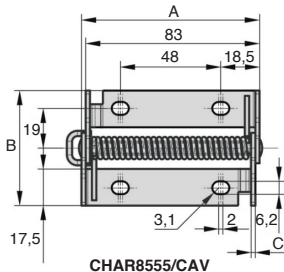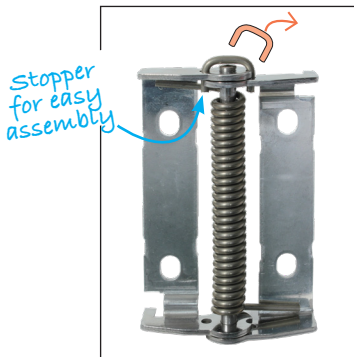

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Type	Weight (g)	Stock*	Price each 1 to 5
CHAR8555/CAV	85	55	2	5	opening	107	-	23,33 €
CHAR8555-F/CAV	85	55	2	5	closing	107	-	23,33 €

*Depending on availability - Dimensions in mm

Our other products




CHM30-MOT

Asynchronous AC motorgearboxes 0.09 to 0.22kW, 0.09 to 0.22kW



MSP19

 Masterplate® glueable insert Ø19/Ø20, Cylindrical with nut



T5courroie

T type timing belt, T5 Steel cored polyurethane



TCL-ECL

Support rod for heavy loads, Support spindle



LRRss

Latch, Spring loaded latch - stainless steel



DOMI30

Connecting kits, XY linking kit



AT10-25ECO

AT type timing pulley, Economy range - AT10 aluminium



PTA80

Articulated levelling foot, pressed base Ø80, Ø 80



CHAPAMss

Weld-on hinge with flat end, Stainless steel or Aluminium



TCLar

Automatic chain tensioner, With wide guide



NK17

Drylin®N miniature guiding system, Width 17 mm



PCLA_M

Technopolymer clamping lever - female, Plastic

Complementary products



CHAR7530

Spring hinge, welded



CHAR6035

Spring hinge, screwed/welded



CHAR7520

Spring hinge, screwed



CHAR16046

Spring hinge, screwed