

# Stainless steel compact spring hinge

## CHARCAV

## Very easy to install

- Spring-loaded hinges with stopper to lock the hinges in the open position for easy assembly

- 270° opening angle

- Material

304 stainless steel, stainless steel spring

- Spring torque

Opening spring:

M(0°): 1.6 Nm

M(90°): 1.2 Nm

M(180°): 0.84 Nm


Closing spring:

M(0°): 0.75 Nm

M(90°): 1.2 Nm


M(180°): 1.65 Nm

stopper for easy assembly


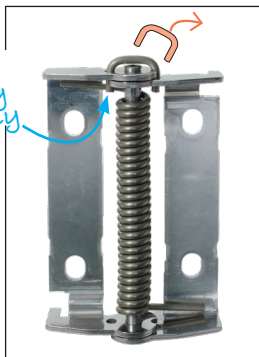


### Info

- Spring hinge opens or closes delivered flat

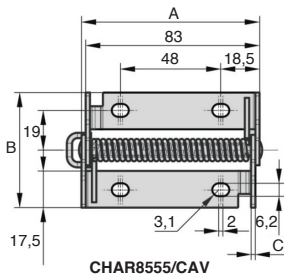

Remove stopper after assembly

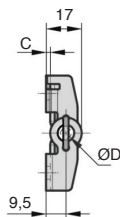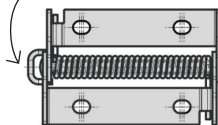

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Type	Weight (g)	Stock*	Price each 1 to 5
CHAR8555/CAV	85	55	2	5	opening	107	-	23,33 €
CHAR8555-F/CAV	85	55	2	5	closing	107	-	23,33 €

\*Depending on availability - Dimensions in mm

## Our other products



DOMI\_MD

Domino rotary table,  
40/1



RPP

Connecting plate for  
RPP type timing belts,  
RPP8



M0

Worm and wheel set,  
Hardened steel



METC

Flanged sintered  
bronze bush, Self-  
lubricating sintered  
bronze



ADL\_F

Female eye bolt  
conforms to DIN582,  
Stainless steel



BAC110

Swivel storage bin,  
Storage bin



ZBconique

Machined plastic  
bevel gear, 1:1



 
ZB

Shaft for linear  
guides, Hardened  
ground stainless steel



RPCtcss

Swivel castor with  
central hole, Stainless



PO

Pull handle - Multi-  
sector, Smooth hole



SH1

Parallel axis helical  
gear, Machined plastic



WJUM10

Drylin® W bearing  
block, Slide

## Complementary products



CHAR7530

Spring hinge, welded



CHAR6035

Spring hinge,  
screwed/welded



CHAR7520

Spring hinge, screwed



CHAR16046

Spring hinge, screwed