


- Polished finish
- Fixed by 8 screws (not supplied)
- Material: stainless steel 304

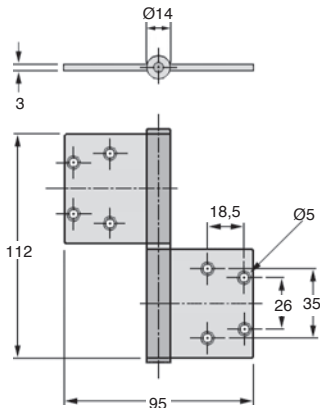

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	Description	Stock*	Price each 1 to 5
CHA-GC-14/SS	Centred hinged plates	✓	41,48 €

*Depending on availability - Dimensions in mm

Our other products



PDM_PDV

Detectable plastic palm grip, blue thermoplastic



PTAF80-PAMF80

Articulated fixable foot with pressed base Ø80, Ø 80



PSG1

Spur gear - precision range, Case hardened steel 20NCD2



G0

Steel spur gear, Steel 20NCD2



HCV

V-rail guidance Simple Select® system, on rail



SLBE

Indexing plunger - Spacer, Spacer for SLB and SLBS index bolts



BLH60

Right angled gearbox, from 19 to 70 Nm



DCG

Suction cup, 2.5 bellows, nitrile



GG3

Ground spur gear, Heat treated steel



INS_SS

Self tapping stainless steel insert, Stainless steel



PRES

Manual workbench press accessory for PRES-3HR end



HTD14M_55

HTD Heavy duty timing pulley, HTD14 Steel

Complementary products



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHAGC-AL

Screw-in garnet hinge, Screw-on