


## Weld-on

## CHAGC<sub>SS</sub> CHAGD<sub>SS</sub>


- To be welded
- Materials:  
Body: stainless steel 316  
Pin: stainless steel

### Advantage

- Allows easy removal of the opening part

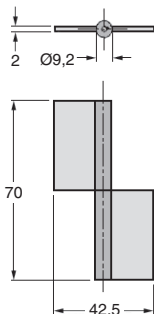

*centred hinge plates*

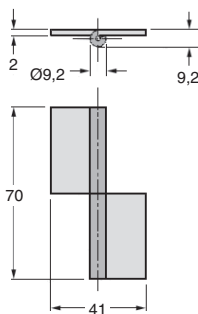

*offset hinge plates*

### DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	Description	Stock*	Price each 1 to 5
CHA-GC-9/SS	Centred hinge plates	✓	19,30 €
CHA-GD-9/SS	Offset hinge plates	✓	18,53 €

\*Depending on availability - Dimensions in mm

## Our other products



HK  
Manual locking clamp,  
Manual locking clamp  
LWL




AFA  
Locking pin, with ring




PCS\_PA6  
Plastic sprocket,  
12.7mm (DIN 08B-1)



HRV  
V-rail guidance  
Simple Select®  
system, Rail with  
carriage

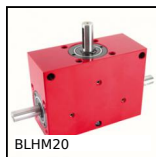

BLHM20  
Right angled gearbox,  
double output shafts,  
up to 1.77 Nm

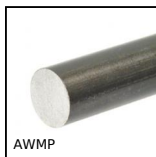

AWMP  
Aluminium shaft for  
linear guide,  
Aluminium



AC144  
Strike for toggle latch,  
22mm



PW\_PWG25  
Wheel - precision  
range, Bronze



CNA-CNG  
Right angled  
mounting plate, Right  
angled mounting



PDM\_PDV  
Detectable plastic  
palm grip, blue  
thermoplastic



SSB  
Stainless steel bevel  
gear, 1:1



PSG085  
Spur gear - precision  
range, Stainless steel  
303

## Complementary products



CHA\_GC\_14SS  
Stainless steel garnet  
hinge, To screw



CHA\_GC\_9SS  
Stainless steel garnet  
hinge, To be welded



CHAGC-AL  
Screw-in garnet  
hinge, Screw-on



CHAGC-AL  
Screw-in garnet  
hinge, Screw-on