

Non-removable pin hinge

CHASB

Black or white plastic hinge

- **Plastic hinge with non-removable pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

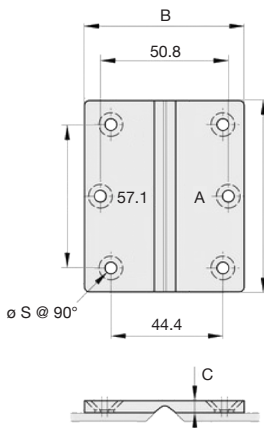

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Price	-5%	-10%	-10%	On request

Part number	A	B	C	ØS	Finishing	Weight (g)	Price per unit
							1 to 5
CHASB63-76/W	76.2	63.5	4.76	4.62	White	16	8,31 €
CHASB63-76/N	76.2	63.5	4.76	4.62	Black	16	8,31 €

*Within the limits of available stock - Dimensions in mm

Non-removable pin hinge

Black or white plastic hinge

CHASB

- Plastic hinge with non-removable pin
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene.
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

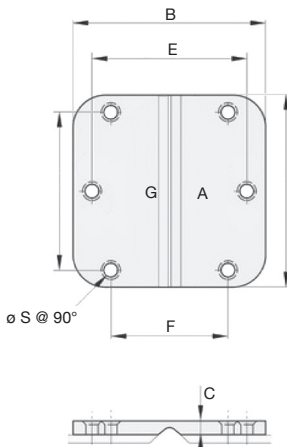

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Price	-5%	-10%	On request

Part number	A	B	C	E	F	G	ØS	Finishing	Weight (g)		Price per unit
											1 to 5
CHASB89-89/W	88.9	88.9	6.35	71.4	54	73	6	White	35		12,17 €
CHASB89-89/N	88.9	88.9	6.35	71.4	54	73	6	Black	35		12,17 €

*Within the limits of available stock - Dimensions in mm

Non-removable roller pin hinge

CHASB

Black or white plastic hinge


- **Non-removable roller pin polymer hinge to be cut to length by the user**
- Offered in rolls of 15.25 meters
- Fastening by screws, rivets, nails or staples
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
 - Polypropylene
- Tensile strength 180N/cm

Advantages

- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use


- Ideal for horizontal use for hinging a hood

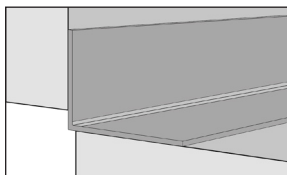

Typical application



Tensile strength

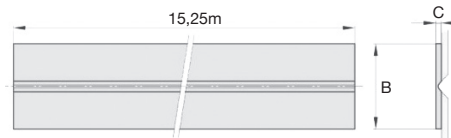

DISCOUNTS

Qty	1+	3+
Disc.	Price	On request

Part number	B	C	Finishing	Weight roll (g)	Price per unit 1 to 2
CHASB28-R/W	28.6	3.2	White	1050	350,67 €
CHASB28-R/N	28.6	3.2	Black	1050	350,67 €
CHASB38-R/W	38.1	3.2	White	1450	431,45 €
CHASB38-R/N	38.1	3.2	Black	1450	431,45 €

 
*Within the limits of available stock - Dimensions in mm

Our other products



RPP

Connecting plate for RPP type timing belts, RPP8



GMK17_P

Flat Guide, Flat guide for conical profile



PRF_GAL

Roller for aluminium profile, Fixing kit for roller concentric



BABpss

301 Stainless steel ball pin, Stainless steel



SH1

Parallel axis helical gear, Machined plastic (delrin)



CLB_T

Die cast zinc clamping lever - male, Zamak



RURt

Swivel castor with central hole, Polyurethane - Aluminium rim (Free



SDB

Locking bolt support bracket, Mounting holes at 90° to locating bolt



SH2

Parallel axis helical gear, Steel 20NCD2



BHEx

Hexagonal cap, Black technopolymer



RPPM

RPP type belt per metre, RPP5 Steel



GAC

Lock for latch clamp, Strike plate

Complementary products



CHAsb63

Hinge without pin, Polymer pin hinge



CHAsb89

Hinge without pin, Plastic hinge