

Non-removable pin hinge

CHASB

Black or white plastic hinge

- **Plastic hinge with non-removable pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

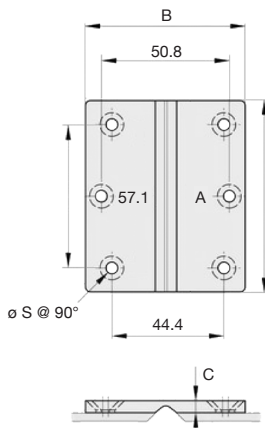

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Price	-5%	-10%		On request

Part number	A	B	C	ØS	Finishing	Weight (g)	Price per unit
							1 to 5
CHASB63-76/W	76.2	63.5	4.76	4.62	White	16	8,31 €
CHASB63-76/N	76.2	63.5	4.76	4.62	Black	16	8,31 €

*Within the limits of available stock - Dimensions in mm

Non-removable pin hinge

Black or white plastic hinge

CHASB

- Plastic hinge with non-removable pin
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene.
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

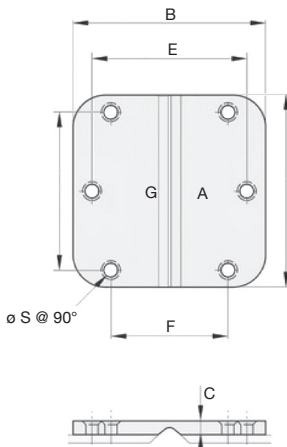

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Price	-5%	-10%	On request

Part number	A	B	C	E	F	G	ØS	Finishing	Weight (g)		Price per unit
									1 to 5	6 to 10	
CHASB89-89/W	88.9	88.9	6.35	71.4	54	73	6	White	35		12,17 €
CHASB89-89/N	88.9	88.9	6.35	71.4	54	73	6	Black	35		12,17 €

*Within the limits of available stock - Dimensions in mm

Non-removable roller pin hinge

CHASB

Black or white plastic hinge


- **Non-removable roller pin polymer hinge to be cut to length by the user**
- Offered in rolls of 15.25 meters
- Fastening by screws, rivets, nails or staples
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
 - Polypropylene
- Tensile strength 180N/cm

Advantages

- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use


- Ideal for horizontal use for hinging a hood

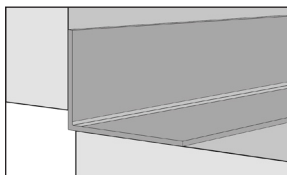

Typical application



Tensile strength

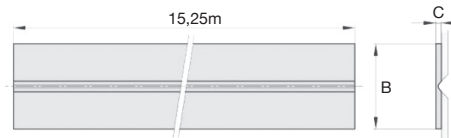

DISCOUNTS

Qty	1+	3+
Disc.	Price	On request

Part number	B	C	Finishing	Weight roll (g)	Price per unit 1 to 2
CHASB28-R/W	28.6	3.2	White	1050	350,67 €
CHASB28-R/N	28.6	3.2	Black	1050	350,67 €
CHASB38-R/W	38.1	3.2	White	1450	431,45 €
CHASB38-R/N	38.1	3.2	Black	1450	431,45 €

 
*Within the limits of available stock - Dimensions in mm

Our other products



T10_21_AL

T type timing pulley,
Economy range - T10
aluminium




GPLac

Brush, steel



DOMI_MD

Domino rotary table,
55/1

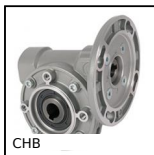

CHB

Worm and wheel gear
reducer, up to 73 Nm




DOMI30

Accessories, Fixing kit



GE_ES

 Spherical bushing,
Steel / steel



CAB

Stainless steel cable,
Stainless steel



CQA20

Accessory for
adjustment slide-
system, 20



LBE

Miniature closed
linear bearing,
Miniature



HBM

Adjustment bushing
for half-rail guide,
Adjustment bushing



WS10

Drylin® W rail, Rail



AT10-32ECO

AT type timing pulley,
Economy range -
AT10 aluminium

Complementary products



CHAsb63

Hinge without pin,
Polymer pin hinge



CHAsb89

Hinge without pin,
Plastic hinge