

Non-removable pin hinge

CHASB

Black or white plastic hinge

- **Plastic hinge with non-removable pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

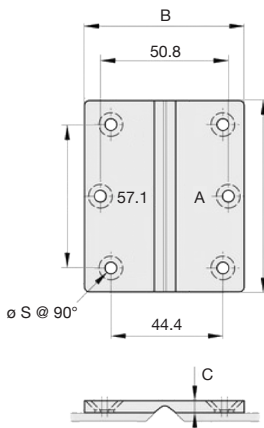

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Price	-5%	-10%	-10%	On request

Part number	A	B	C	ØS	Finishing	Weight (g)	Price per unit
							1 to 5
CHASB63-76/W	76.2	63.5	4.76	4.62	White	16	8,31 €
CHASB63-76/N	76.2	63.5	4.76	4.62	Black	16	8,31 €

*Within the limits of available stock - Dimensions in mm

Non-removable pin hinge

Black or white plastic hinge

CHASB

- Plastic hinge with non-removable pin
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene.
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

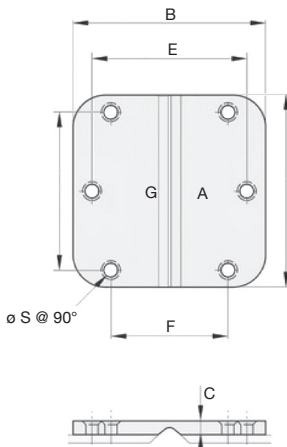

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Price	-5%	-10%	On request

Part number	A	B	C	E	F	G	ØS	Finishing	Weight (g)		Price per unit
									1 to 5	6 to 10	
CHASB89-89/W	88.9	88.9	6.35	71.4	54	73	6	White	35		12,17 €
CHASB89-89/N	88.9	88.9	6.35	71.4	54	73	6	Black	35		12,17 €

*Within the limits of available stock - Dimensions in mm

Non-removable roller pin hinge

CHASB

Black or white plastic hinge


- **Non-removable roller pin polymer hinge to be cut to length by the user**
- Offered in rolls of 15.25 meters
- Fastening by screws, rivets, nails or staples
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
 - Polypropylene
- Tensile strength 180N/cm

Advantages

- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use


- Ideal for horizontal use for hinging a hood

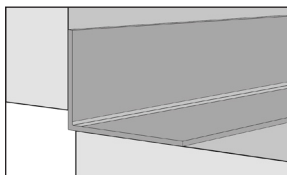

Typical application



Tensile strength

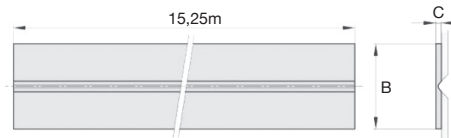

DISCOUNTS

Qty	1+	3+
Disc.	Price	On request

Part number	B	C	Finishing	Weight roll (g)	Price per unit 1 to 2
CHASB28-R/W	28.6	3.2	White	1050	350,67 €
CHASB28-R/N	28.6	3.2	Black	1050	350,67 €
CHASB38-R/W	38.1	3.2	White	1450	431,45 €
CHASB38-R/N	38.1	3.2	Black	1450	431,45 €

*Within the limits of available stock - Dimensions in mm

Our other products



RHTplss

High Temperature
Castor, up to 200kg



ZG0

Plastic spur gear,
Machined plastic
(delrin)



RBNpl

Swivel castor with
double brake, Steel -
rubber



PR882

Idler sprocket for slat
top chain, Range 882



RBGtc

Swivel castor with
central hole, Steel -
grey rubber



BABTV

Ball lock pins lockable
, Stainless steel



SSB

Stainless steel bevel
gear, 1:1



BABpss

301 Stainless steel
ball pin, Stainless
steel




GLB

Small 6 lobe threaded
handle - female,
Technopolymer -



NK17

Drylin®N miniature
guiding system, Width
17 mm

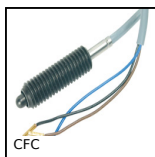

CFC

Spring loaded position
switch, Electric
contact



PF60

Worm and wheel gear
reducer, up to 118
Nm

Complementary products



CHAsb63

Hinge without pin,
Polymer pin hinge



CHAsb89

Hinge without pin,
Plastic hinge