

Non-removable pin hinge

CHASB

Black or white plastic hinge

- **Plastic hinge with non-removable pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

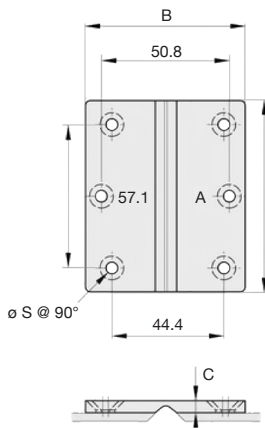

DISCOUNTS

| | | | | |
|-------------|-----|------|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. Price | -5% | -10% | -10% | On request |

| Part number | A | B | C | ØS | Finishing | Weight (g) | Price per unit | |
|--------------|------|------|------|------|-----------|------------|----------------|--------|
| | | | | | | | 1 to 5 | |
| CHASB63-76/W | 76.2 | 63.5 | 4.76 | 4.62 | White | 16 | | 8,31 € |
| CHASB63-76/N | 76.2 | 63.5 | 4.76 | 4.62 | Black | 16 | | 8,31 € |

*Within the limits of available stock - Dimensions in mm

Non-removable pin hinge

Black or white plastic hinge

CHASB

- Plastic hinge with non-removable pin
- Fastening with screws or rivets.
- Working tempertaure range: -40° C to 80°C
- 270° opening angle
- Material:
Polypropylene.
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention de material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strenght

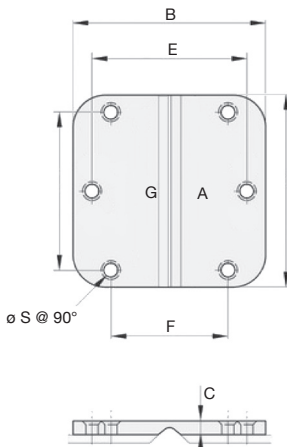

DISCOUNTS

| | | | | |
|-------|-------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | Price | -5% | -10% | On request |

| Part number | A | B | C | E | F | G | ØS | Finishing | Weight (g) | | Price per unit |
|--------------|------|------|------|------|----|----|----|-----------|------------|--|----------------|
| | | | | | | | | | | | 1 to 5 |
| CHASB89-89/W | 88.9 | 88.9 | 6.35 | 71.4 | 54 | 73 | 6 | White | 35 | | 12,17 € |
| CHASB89-89/N | 88.9 | 88.9 | 6.35 | 71.4 | 54 | 73 | 6 | Black | 35 | | 12,17 € |

*Within the limits of available stock - Dimensions in mm

Non-removable roller pin hinge

CHASB

Black or white plastic hinge


- **Non-removable roller pin polymer hinge to be cut to length by the user**
- Offered in rolls of 15.25 meters
- Fastening by screws, rivets, nails or staples
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
 - Polypropylene
- Tensile strength 180N/cm

Advantages

- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use


- Ideal for horizontal use for hinging a hood

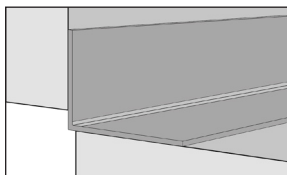

Typical application



Tensile strength

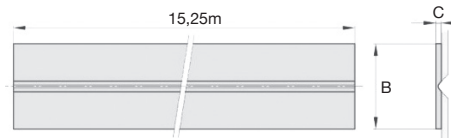

DISCOUNTS

| | | |
|-------|-------|------------|
| Qty | 1+ | 3+ |
| Disc. | Price | On request |

| Part number | B | C | Finishing | Weight roll (g) | Price per unit 1 to 2 |
|-------------|------|-----|-----------|-----------------|-----------------------|
| CHASB28-R/W | 28.6 | 3.2 | White | 1050 | 350,67 € |
| CHASB28-R/N | 28.6 | 3.2 | Black | 1050 | 350,67 € |
| CHASB38-R/W | 38.1 | 3.2 | White | 1450 | 431,45 € |
| CHASB38-R/N | 38.1 | 3.2 | Black | 1450 | 431,45 € |

*Within the limits of available stock - Dimensions in mm

Our other products



CM

Tools Hygienic Usit® and Hygienic Design®, Combination spanner



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2




SH3

Parallel axis helical gear, Machined plastic (delrin)



SHNbr

 Hexagonal nut DIN934, Brass



KB_OP

Open precision linear bearing, Precision - steel



TMR

Rigid manual tensioner, Adjustable



NT92

Spur gear coaxial gearbox, from 15 to 40 Nm - In-line



F7-P-AM

Multifunction display, Magnetic ring



BPL

Ball transfer unit light duty, Light



PLM-C

Cylindrical holding magnets, Cylindrical



LVT

Miniature motorised actuator 2A, 2 amperes



PLB

Cylindrical spacer, Brass

Complementary products



CHAsb63

Hinge without pin, Polymer pin hinge



CHAsb89

Hinge without pin, Plastic hinge