

# Hinge without pin

## CHASB

## Black or white plastic hinge

- **Polymer hinge without pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:  
Polypropylene
- Tensile strength 180N/cm

### Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

### Use

- Ideal for horizontal use for hinging a hood



Tensile strength

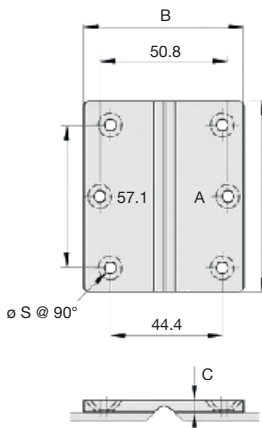

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Price	-5%	-10%	-10%	On request

Part number	A	B	C	ØS	Finishing	Weight (g)	Price per unit
							1 to 5
CHASB63-76/W	76.2	63.5	4.76	4.62	White	16	8,31 €
CHASB63-76/N	76.2	63.5	4.76	4.62	Black	16	8,31 €

\*Within the limits of available stock - Dimensions in mm

## Our other products



 
MFBSC

Stainless steel flexible bellows coupling, Stainless steel - with cl...



WSS

Symmetrical S shaped hook, Steel



PO

Pull handle - Multi-sector, Smooth hole



 
KKP-AR

Linear bearing with inclined ball tracks, Heavy loads / -20° +200°



PRF\_PA

Angle plate for aluminium profile, Adjustable plate



RPPM

RPP type belt per metre, RPP5 Steel cored polyurethane



SUA4\_L

Chain link, Steel



ZDB

Machined plastic bevel gear, 2:1



GLP

Small 6 lobe threaded handle - male,



SCH

Horizontal hook toggle clamp,



DB

Steel bevel gear, 2:1



CHB

Worm and wheel gear reducer, up to 73 Nm

## Complementary products



CHAsb89

Hinge without pin, Plastic hinge



CHAsb28

Roll of hinge without pin, Plastic hinge