

Hinge without pin

CHASB

Black or white plastic hinge

- **Polymer hinge without pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

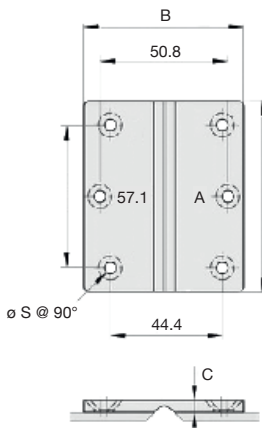

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Price	-5%	-10%	-10%	On request

Part number	A	B	C	ØS	Finishing	Weight (g)	Price per unit
							1 to 5
CHASB63-76/W	76.2	63.5	4.76	4.62	White	16	8,31 €
CHASB63-76/N	76.2	63.5	4.76	4.62	Black	16	8,31 €

*Within the limits of available stock - Dimensions in mm

Our other products



TS01_TW01

Drylin® T linear slide,
up to 7000 N




M2

Worm and wheel set,
Hardened steel



AKN

Bellows coupling
Gerwah®, from 22 to
180Nm

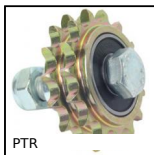

PTR

Idler chain sprocket,
For standard
applications



BS2

Panamech, Multi-
Beam, Aluminium -
with set screw



UTKpwr

V shaped channel
UtiliTrak®, V rail



BCM_T

Driving collar, Driving
collar



NTM

Nylon tipped set
screw, Nylon-point



NT61

Spur gear coaxial
gearbox, from 5 to 14
Nm - Inline



KBS_UU

Stainless steel closed
precision linear
bearing, Precision -



VTHA

Magnetic screw with
hexagonal head, Steel



RFK28B

Hypoid gearbox -
Stainless steel, up to
130 Nm

Complementary products



CHAsb89

Hinge without pin,
Plastic hinge



CHAsb28

Roll of hinge without
pin, Plastic hinge